

PRODUCT FAMILY DATASHEET

OUTDOOR FACADE INDIRECT

Luminaires with rotatable head and indirect light



AREAS OF APPLICATION

- Outdoor
- Building facades
- Decorative illumination

PRODUCT BENEFITS

- Energy-efficient thanks to LED technology
- 5 years guarantee
- Easy and quick installation
- Homogeneous light output

PRODUCT FEATURES

- Bright and functional outdoor LED luminaires
- Type of protection: IP54
- Die-cast aluminum housing
- Available in two housing colors: white and dark gray
- Swivel angle: 90°
- Diffuser made of opal PMMA




TECHNICAL DATA

	Electrical data	Photometrical data	Light technical data	Dimensions & weight			Colors & materials	Temperatures & operating conditions	Lifespan	Additional product data
Product description	Nominal wattage	Luminous flux	Beam angle	Diameter	Height	Product weight	Product color	Ambient temperature range	Lifespan L70 at 25 °C	Mounting type
O FACADE IND RD 13 W 3000 K IP54 GY ¹⁾	13.00 W	480 lm	240 °	150.0 mm	118.0 mm	790.00 g	Gray	-20...40 °C	30000 h	Surface
LED FACADE INDIRECT 13 W 3000 K RD WT ¹⁾	13.00 W	640 lm	240 °	150.0 mm	118.0 mm	790.00 g	White	-20...40 °C	30000 h	Surface


Product description	Mounting location	Capabilities	Certificates & standards			
		Dimmable	Type of protection	Protection class	Protection class IK (shock resistance)	Photobiological safety group
O FACADE IND RD 13 W 3000 K IP54 GY ¹⁾	Wall	No	IP54	I	IK06	RG 0
LED FACADE INDIRECT 13 W 3000 K RD WT ¹⁾	Wall	No	IP54	I	IK06	RG 0

Product description	Standards
O FACADE IND RD 13 W 3000 K IP54 GY ¹⁾	CE
LED FACADE INDIRECT 13 W 3000 K RD WT ¹⁾	CE

¹⁾ Available from February 2018

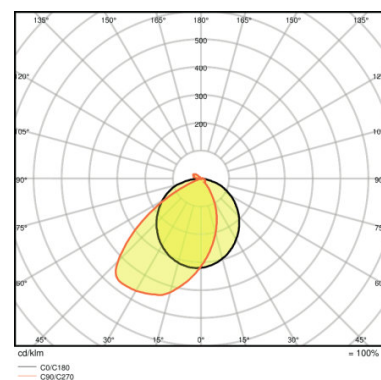

O FACADE IND RD 13 W 3000 K IP54 GY

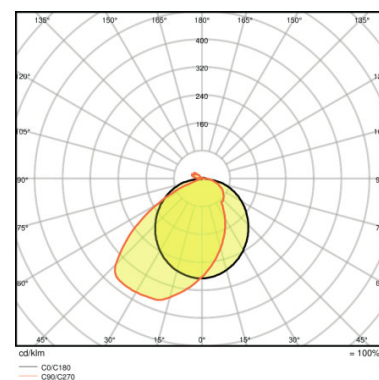LED FACADE INDIRECT 13 W 3000 K RD
WT

EQUIPMENT / ACCESSORIES

- Complete mounting and connecting accessories included

APPLICATION ADVICE

For more detailed application information and graphics please see product datasheet.

LOGISTICAL DATA

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4058075075016	O FACADE IND RD 13 W 3000 K IP54 GY	Shipping carton box 6	300 mm x 275 mm x 185 mm	15.26 dm ³	5308.00 g
4058075075030	LED FACADE INDIRECT 13 W 3000 K RD WT	Shipping carton box 6	300 mm x 275 mm x 185 mm	15.26 dm ³	5308.00 g

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
--------------	---------------------	------------------------------	--------------------------------------	--------	--------------

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

REFERENCES / LINKS

For Guarantee see

▶ www.ledvance.com/guarantee

DISCLAIMER

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.