



Philips myGarden
Wall light

Raccoon
anthracite
LED

myGarden

17273/93/16



Enjoy a beautiful garden with light

The Philips myGarden Raccoon wall light in structured anthracite grey lights up outdoor areas powerfully for whatever you like. LED lights, synthetic materials and minimalist design give a contemporary feel to your outdoor space.

Designed for your garden

- IP44 - weather proof

Sustainable light solutions

- High quality LED light
- Philips offers 5 year warranty on the LED module and driver
- Energy saving
- Warm white light
- Long operating life up to 15 years

PHILIPS

Highlights

High quality LED light




The LED technology, integrated into this Philips lamp, is a uniquely developed solution by Philips. While instantly turned on, it enables an optimal light output and brings out vivid colors in your home.

5 year warranty on LED system



On top of the standard 2 year warranty for this lamp, Philips offers 5 year warranty on the LED system, meaning the LED module and the driver in this lamp.

Warm white light

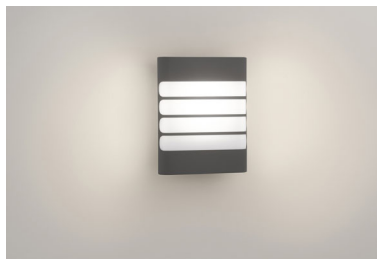

Light can have different color temperatures, indicated in units called Kelvin (K). Lamps with a low Kelvin value produce a warm, more cosy light, while those with a higher Kelvin value produce a cool, more energising light. This Philips lamp offers warm white light for a cosy atmosphere.

Energy saving



This Philips energy saving lamp conserves energy compared to traditional light sources, helping you to save money on your electricity bills and do your bit for the environment.

IP44 - weather proof



This Philips outdoor light is especially designed for humid outdoor environments. It was tested rigorously to ensure its water resistance. The IP level is described by two figures: the first one refers to the protection level against dust, the second against water. This outdoor light is designed with IP44: it is protected against splashing water, this product is most common and ideal for general outdoor use.

Long operating life



A light source you can trust. The integrated LEDs, used in this Philips LED lamp, will last up to 15.000 hours (which equals 15 years on basis of an average use of 3 hours / day with an amount of at least of 13.000 on/off switching cycles). It feels so comfortable to think that you won't have to worry about maintenance or light bulb replacement while having the perfect light ambience in your home.

Specifications

Design and finishing

- Material: synthetics, stainless steel
- Colour: anthracite

Extra feature/accessory incl.

- Fully weatherproof
- 5 years warranty on the LED module

Product dimensions & weight

- Height: 20.5 cm
- Length: 16.2 cm
- Width: 6.6 cm
- Net weight: 0.620 kg

Technical specifications

- Mains power: Range 220 V - 240 V, 50-60 Hz
- Bulb technology: LED, Safety Extra Low Voltage
- Number of bulbs: 1
- Wattage bulb included: 3 W
- Light colour: warm white
- Total lumen output fixture: 270 lm

- Fixture dimmable: No
- LED
- Lifetime up to: 25,000 hrs
- IP code: IP44, protection against objects bigger than 1 mm, protection from splashed water
- Class of protection: II - double insulated
- Light source equivalent to traditional bulb of: 30 W

Service

- Warranty: 5 year(s)

Packaging dimensions & weight

- Height: 22.8 cm
- Length: 16.3 cm
- Width: 7.8 cm
- Weight: 0.683 kg

Miscellaneous

- Especially designed for: Garden & Patio
- Style: Contemporary
- Type: Wall light



Issue date 2018-01-24

Version: 2.0.1

12 NC: 9150 043 08701
EAN: 87 18291 47946 8

© 2018 Philips Lighting Holding B.V.
All Rights reserved.

Specifications are subject to change without notice.
Trademarks are the property of Philips Lighting Holding B.V. or their respective owners.

www.philips.com