



HT550R + HT550

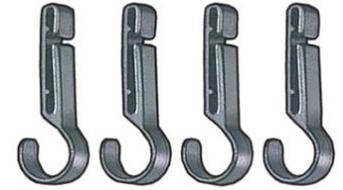

The HT550 and HT550R can both be helmet mounted

2 Models available

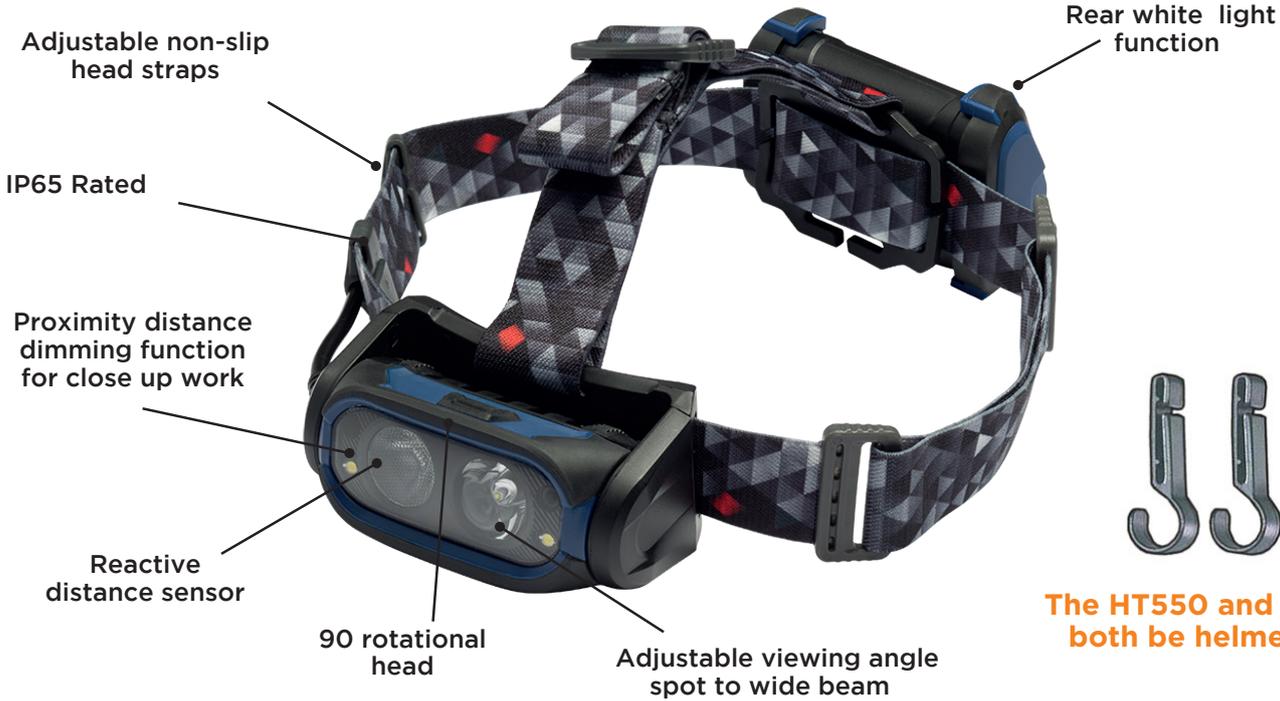

Powered by Rechargeable
LI-ION
Technology

Powered by 4x



Rechargeable

HT550R Key features:

- Rechargeable Li-ion head torch
- 550 Lumens light output
- 550m beam
- 3 Light modes: spot, wide beam and distance dimming
- Rechargeable via USB cable
- Runtime: 7.5hrs high | 169hrs low

Optional extras:

- AC/DC vehicle charging adaptors
- Helmet clips

Non Rechargeable

HT550 Key features:

- Powered by 4 x AA batteries
- 550 Lumens light output
- 550m beam
- 3 Light modes: spot, wide beam and distance dimming
- Runtime: 7.5hrs high | 169hrs low



PRODUCT CODE	DIMENSIONS
NSHT550R	(L)85X(D)42X(H)48mm (Head) (L)84X(D)40X(H)50mm (Battery pack)
CAT/PAD: 0111/11269	



PRODUCT CODE	DIMENSIONS
NSHT550	(L)85X(D)42X(H)48mm (Head) (L)84X(D)40X(H)50mm (Battery pack)