


# Product information

## 230MM ANGLE GRINDER



### GA9020S

Bore Diameter	22 mm
Noise sound pressure	89 dB(A)
Noise sound power	100 dB(A)
Noise K factor	3 dB(A)
Spindle Size	M14x2mm
Max Wheel Diameter	230 mm
Input wattage	2000 w
No Load Speed	6600 rpm
Vibration K factor	1.5 m/sec <sup>2</sup>
Vibration: Artificial Wheel	5.5 m/sec <sup>2</sup>
Net weight	5.85 - 8.14 kg

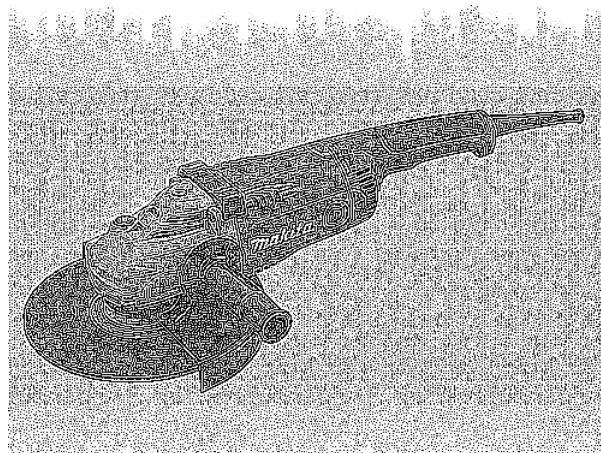

**STANDARD EQUIPMENT:** Lock nut wrench, Side handle

- Superior Anti-Dust Structure
- Machined bevel gears.
- Greater heat resistance
- Gear housing can be positioned at every 90 degrees.
- Soft start feature.

Details correct as of: 6-7-2018

Makita reserve the right to change specifications at any time owing to their policy of constant improvement.

Accessories shown are not necessarily supplied.

[www.makitauk.com](http://www.makitauk.com)