


 
Material number	0 601 066 100
EAN	3165140527149
3 x 1.5 V LR6 battery AA	✓
Multifunctional mount spare part number 1 618 C00 465	✓
Protective bag	✓



## Technical data

### Technical data

Laser diode	635 nm, < 1 mW
Operating temperature	-10 – 40 °C
Storage temperature	-20 – 70 °C
Laser class	2
Working range	30 m
Accuracy	± 0.3 mm/m
Self-levelling range	± 5° longitudinal axis, ± 3° traverse axis
Levelling time	4 s
Dust and splash protection	IP 5X
Beam diameter	5 mm on tool
Power supply	3 x 1.5 V LR6 (AA)
Operating time (max.)	24 h
Tripod thread	1/4", 5/8"
Weight, approx.	0.25 kg
Projection	3 points

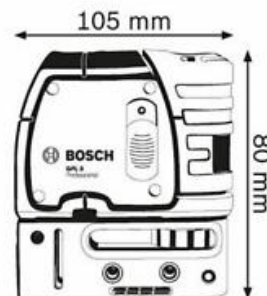

## Sales information

---

### Positioning

- Highly compact 3-point laser – ideal for plumb point transfer

### User benefit incl. Reason to believe

- Self-levelling 3-point horizontal and plumb laser for indoor work
- Enables precise transfer of a reference point from the ground to the ceiling
- Easy handling due to its very compact size

