

UNILITE INDUSTRIAL HIGH POWER HEADLIGHT

PS-
HDL9R

NEW



4-260
HOURS
RUNTIME

100
METRE
BEAM RANGE

750
LUMENS
OUTPUT


IPX6
WATER
RESISTANCE

- » 750 Lumen white CREE LED
- » High power Li-ion batteries (included)
- » Parallel circuitry - runs off 1 or 2 batteries
- » Micro-USB rechargeable (cable included)
- » Anti-dazzle retractable light shield
- » Wider angle light spread
- » Easy twist smooth dimming power switch
- » Red rear battery pack light (on & flash)
- » 45° rotational head
- » Fully adjustable non-slip silicone headbands
- » IPX6 water resistance
- » Presented in hard zipped storage case

BATTERY 2 x 3.7v 2000mAh Li-ion Batteries (included)
WEIGHT 275g (with 2 batteries)
DIMENSION Headlight: 38 x 60x 45mm - Battery Pack: 65 x 90 x 45mm

USB
CHARGING

LIGHT BY
CREE
LEDs

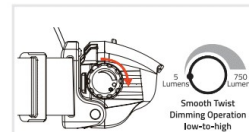

EASY TWIST SMOOTH DIM SWITCH



ANTI-DAZZLE LIGHT SHIELD



NON-SLIP SILICONE HEADBANDS



RED REAR BATTERY PACK LIGHT