

632629

European Region

Strong, light and work-friendly construction in a compact size – that's the Energizer[®] Impact Rubber. This light features a non-slip textured rubber handle and a pushbutton switch that's easy to operate, even when wearing gloves. In addition, it's ready for when you need both hands; just flip down the built in stand.

HANDS-FREE

- Built in stand
- Non-roll design



CONVENIENT

- Textured handle for non-slip grip
- Pushbutton switch large enough to use while wearing gloves



BRIGHT

- Two white Nichia LEDs provide 26 lumens



ECONOMICAL

- LEDs never need replacing
- 15½ hours of use between battery changes (using Energizer Max AA batteries)




Before Using Your Flashlight:
Please read all instructions and cautionary markings on the package and light

European Region Product Detail:

Designation: Energizer
Impact Rubber 2AA
SAP: 632629
Colour: Red and Black
Power Source: Two "AA"
IEC: LR6
Lamp: Two White LEDs
Lamp Life (hr): Lifetime
Light Output (lumens): 26
Run Time (h:min): 15:30
Beam Distance (m): 30
Peak Beam Intensity (cd): 225
Typical Weight: 222 grams
without batteries
Dimensions (mm): 72 x 190

Performance:

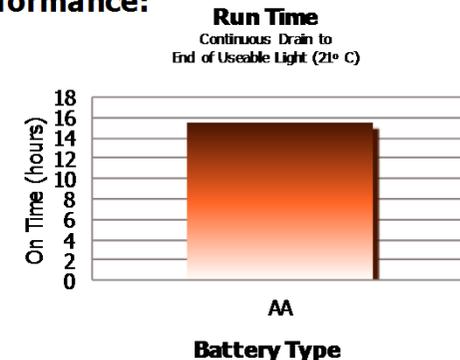

Important Notice

This datasheet contains information specific to products manufactured at the time of its publication
Contents herein do not constitute a warranty
©Energizer / All Rights Reserved