

632630

European Region

Strong, light and work-friendly construction in a compact size – that's the Energizer® Impact Rubber Light. Sturdy construction helps the light survive a 1-metre drop. It features a non-slip textured rubber handle and a pushbutton switch that's easy to operate, even when wearing gloves. In addition, it's ready for when you need both hands; just flip down the built in stand.

HANDS-FREE

- Built in stand
- Non-roll design



CONVENIENT

- Textured handle for non-slip grip
- Pushbutton switch large enough to use while wearing gloves



BRIGHT

- The white LED provides 12 lumens



ECONOMICAL

- LEDs never need replacing
- 12 hours of use between battery changes (using Energizer® Max AAA batteries)



Before Using Your Flashlight:
Please read all instructions and cautionary markings on the package and light

European Region Product Detail:

Designation: Energizer
Impact Rubber 2AAA

SAP: 632630

Colour: Red and Black

Power Source: Two "AAA"

IEC: LR03

Lamp: One White LED

Lamp Life (hr): Lifetime

Light Output (lumens): 12

Run Time (h:min): 12

Beam Distance (m): 27


Peak Beam Intensity (cd): 182

Typical Weight: 103 grams
without batteries

Dimensions (mm): 55 x 149

Performance:

Run Time
Continuous Drain to
End of Useable Light (21° C)

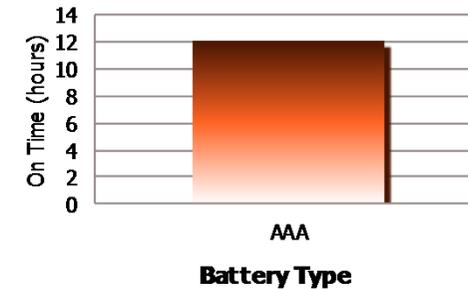

Important Notice

This datasheet contains information specific to products manufactured at the time of its publication
Contents herein do not constitute a warranty
©Energizer / All Rights Reserved