


Energizer®

Outdoor

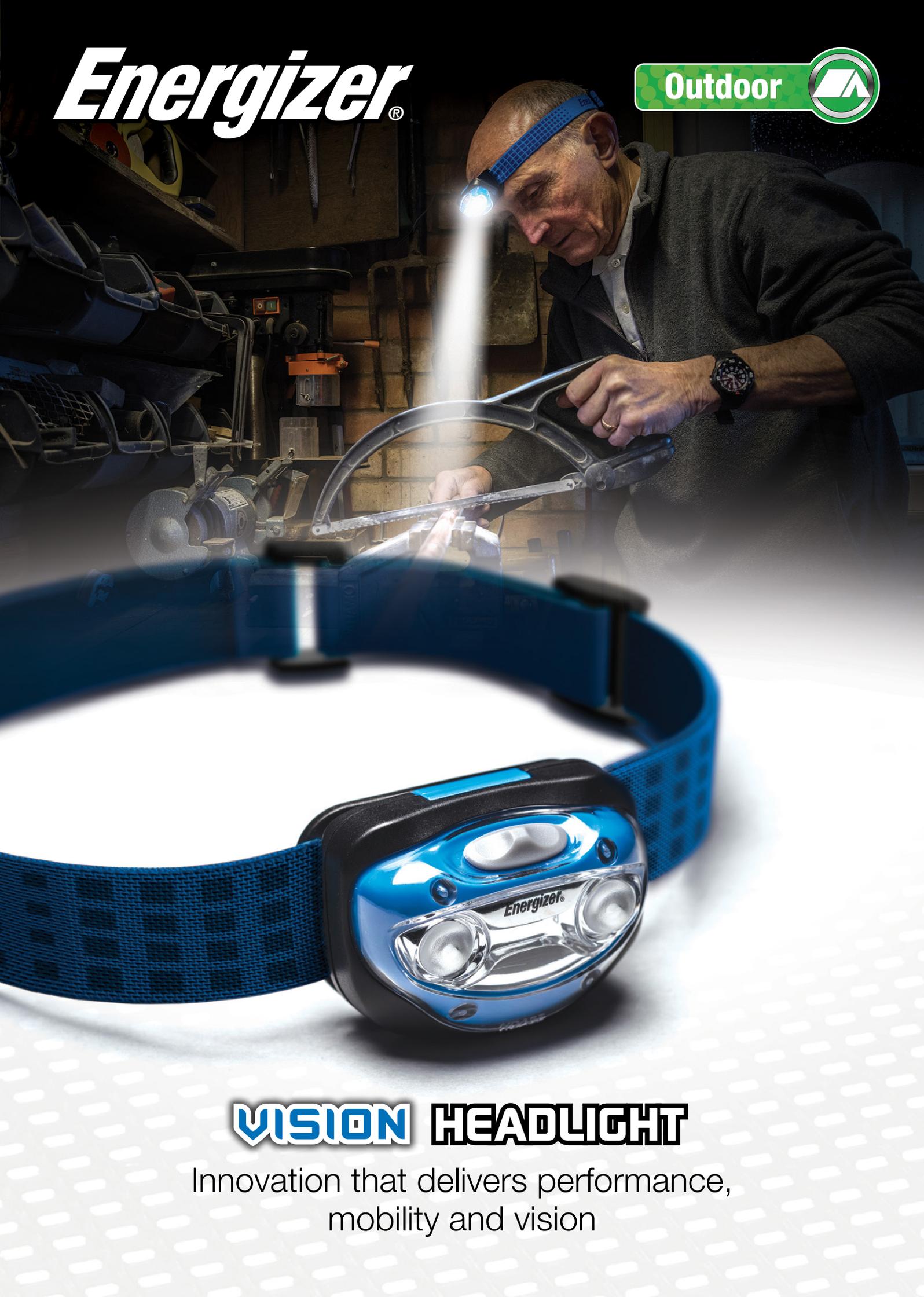

VISION HEADLIGHT

Innovation that delivers performance,
mobility and vision



New and improved vs. previous range,
Up to **4X brighter** vs. ordinary LED's



VISION HEADLIGHT

- 2 white LEDs
- High & low power light modes
- On/off slide switch
- Adjustable elastic headband
- Pivoting head
- Shatter proof lens
- Survives a 1 meter drop
- Designed to last 15 years
- 3 x AAA Alkaline batteries included



Brightness



Runtime¹



Beam Distance



Weatherproof²

SPECIFICATIONS	SAP/GMN	E300280301	Outdoor
	MODEL	HDA321	
	EAN	7638900270228	
	ITF	17638900270225	
	TORCH CU/SU	1/6	
	DIMENSIONS CU (mm) (H,W,D)	190.5 x 147.3 x 39.4	
	DIMENSIONS SU (mm) (H,W,D)	203.2 x 282.575 x 161.925	
	WEIGHT (Kg) CU/SU	0.116/0.920	
	SU DETAILS	Single facing tray	
	BATTERIES	3 x AAA	
BULB	2 x White LED		



¹Based on a fresh set of Energizer® Max® AAA batteries in high mode. ²Weatherproof to IPX4 (not submersible)

FOR MORE INFORMATION ON ALL OUR LIGHTING
PRODUCTS VISIT: www.energizer.eu