

Pliers and Cutters — with Red Cushion Grip Handles



The exceptional strength and performance of Xcelite® pliers and cutters are the result of forged alloy steel construction, precision machining, and scientific proportioning

Handles designed to fit the hand comfortably and to provide maximum leverage


Cleanly machined and perfectly aligned jaws grip tightly and surely while easy cutting is assured by hand-honed, mated cutting edges

For extra working comfort all models have permanent, red plastic-coated “Cushion-Grip” handles except Combination Slip Joint pliers

These high quality pliers and cutters are featured in Xcelite® Attachê Tool Cases

	WARNING	AVERTISSEMENT	ADVERTENCIA
	Risk Of Eye Injury Wear ANSI Approved Eye Protection	Risque de dommages d'oeil Protection d'oeil approuvée de l'usage A.N.S.I.	Riesgo de lesión del ojo Protección de ojo aprobada del desgaste ANSI


Hard Wire (Piano and Music) Cutter 134CG

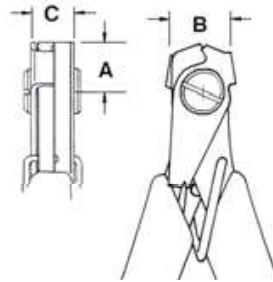

- Shear cutting action
- Ensures square cut ends
- Captures material on both sides of jaw, eliminates flying segments
- Patented spring loaded hold-down keeps material at 90° to tool blade
- Prevents material from forcing jaws apart
- Wire capacity .062
- Stranded cable capacity 1/16"

Catalog Number	UPC Number	Packed	Length (inch)	Length (mm)	A (inch)	A (mm)	B (inch)	B (mm)	C (inch)	C (mm)	Pack weight (lb)	Pack weight (g)	Shelf pack
134CG	037103059994	Bagged	5.45	140	0.55	14	0.72	18.5	0.32	8.2	18.4	522	6

Diagonal Pliers 54CG

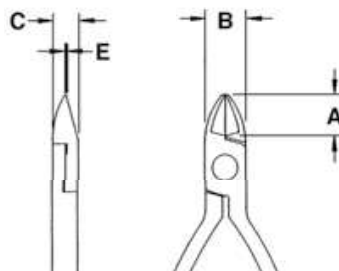

- For work in close quarters
- Oval head
- Standard beveled edges
- Forged alloy steel construction, precision machining and scientific proportioning
- Red plastic-coated cushion grip provides maximum leverage

Catalog Number	UPC Number	Packed	Length (inch)	Length (mm)	A (inch)	A (mm)	B (inch)	B (mm)	C (inch)	C (mm)	E (inch)	E (mm)	Pack weight (lb)	Pack weight (g)	Shelf pack
54CGV	037103481597	Carded	4	100	13/32	10	7/16	11	9/32	7	1/32	0.8	12.5	354	6