


# In Wall Speakers

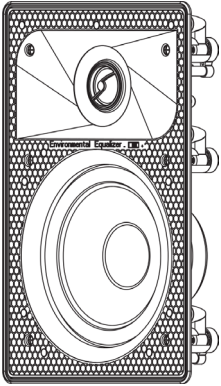

## Speciafication Table

Part Number	555-29845	555-29850	555-29855
Woofer	5.25" Kevlar Type Woven Cone	6.5" Kevlar Type Woven Cone	8" Kevlar Type Woven Cone
Tweeter	1" Titanium Dome	1" Titanium Dome	1" Titanium Dome
RMS Power	40W	60W	80W
Nominal Impedance ( $\Omega$ )	8	8	8
Sensitivity(dB)	90	90	90
Frequency Response( $\pm$ 3dB)	70Hz-20kHz	60Hz-20kHz	50Hz-20kHz
Product Dimensions(mm)	267mm×175mm×75mm (10.5"×6.9"×3")	300mm×205mm×86.5mm (11.8"×8.1"×3.4")	362mm×242mm×105mm (14.3"×9.5"×4.1")
Cutout Diameter(mm)	245mm×155mm (9.6"×6.1")	280mm×185mm (11"×7.3")	340mm×220mm (13.4"×8.7")

## Part Number Table

Description	Part Number
5.25, 2-Way In-Wall Speaker	555-29845
6.5, 2-Way In-Wall Speaker	555-29850
8, 2-Way In-Wall Speaker	555-29855