

VII. Support MHL smart Phone series

Samsung	I9100,i9108,i9188,I977,Samsung Galaxy Note(i900)
HTC	HTC sensation(HTC G14/G18/G19),HTC Flyer, HTC EVO 3D Z710,Z710e,Z710T
LG	LU6200, LG P940
SONY	LT26I
NOKIA	N10

Because of the different connectors, The Samsung smart phone Galaxy S3,S4 series

(I9300,I9308,1939, Note2 N7100,I9500) needs to add a micro USB 5pin to 11 pin connector.

MHL Lead NOT SUPPLIED (optional extra).



5

PRODVC11

MINI
MHL/HDMI TO SCART Converter
User manual

©BlakeUK2016 All Rights Reserved E &OE Product Specifications may be changed without prior notice.

Join the PROfessional's PROcession to PROception!

Thank you for purchasing this product. For optimum performance and safety, please read these instructions carefully before connecting, operating or adjusting this product. Please keep this manual for future reference.

I. Introduction

The mini MHL/HDMI to SCART converter will convert digital MHL/HDMI video and audio signals to composite video signals and stereo audio signals. Converts the high quality of the HDMI signal and smart phone MHL signals to normal CVBS signals (standard definition 480i, 576i), so that it can play on CRT TV, VHS VCR and DVD players etc. Ideal for CCTV DVR's that don't have composite output. Convert the HDMI to composite and then you will be ready to modulate. The MHL/HDMI to SCART converter supports NTSC and PAL TV format outputs.

II. Features

1. No need to install drivers, portable, flexible, plug and play.
2. High quality scaling technology for input resolutions.
3. Support NTSC and PAL two standard TV formats output.
4. Compatible with HDMI1.3.
5. Share your smart phone photos, music and movies on the TV.

III. Package

1. Mini MHL/HDMI to AV Converter-----1PC
2. 5V1A DC Power Supply Adapter(or USB Cable) -----1PC
3. MHL to HDMI Cable(optional) -----1PC
4. Operation Manual-----1PC


IV. Specifications

Input ports 1xHDMI
 Output ports 1xSCART
 Dimensions(mm) 8(D)x58(W)x26(H)
 Weight (g) 45
 Input Resolution 640x480@60Hz,800x600@60Hz, 1024x768@60Hz, 1280x720@60Hz.

1280x1024@60Hz,1360x768@60Hz, 1600x1200@60Hz,1920x1080@60Hz
 480i/60Hz,480p/60Hz,576i/60Hz,576p/60Hz,,
 720p50/60Hz, 1080i50/60Hz,1080p23.97/24/25/50/59.94/60Hz

CVBS output	PAL, NTSC
Operating Temperature	0°C ~ 40°C / 32°F ~ 104°F
Storage Temperature	-20°C ~ 60°C / -4°F ~ 140°F
Relative Humidity	20 ~ 90% RH (Non-condensing)
Power Consumption (Max)	3W

V. Operation controls and Functions

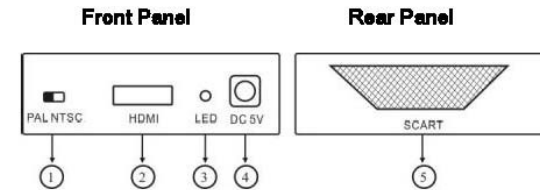

- 1) PAL/NTSC Switch: Switch the CVBS output format.
- 2) HDMI Input: Connect the HDMI to your source equipment such like DVD/Game console.
 Connect the MHL >HDMI to your smart phone
- 3) LED indicator: When the DC5V power on, the indicator will be light.
- 4) Power: Plug the 5VDC power supply into the unit and connect the adapter to AC wall outlet.
- 5) SCART output: Connect the SCART output to your display equipment(like TV SET)

VI. Application Example

