
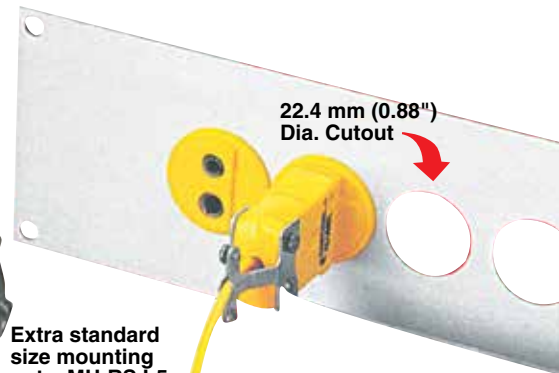


Round Hole Panel Jacks

Type RSJ Standard Size


Type RMJ Miniature Size

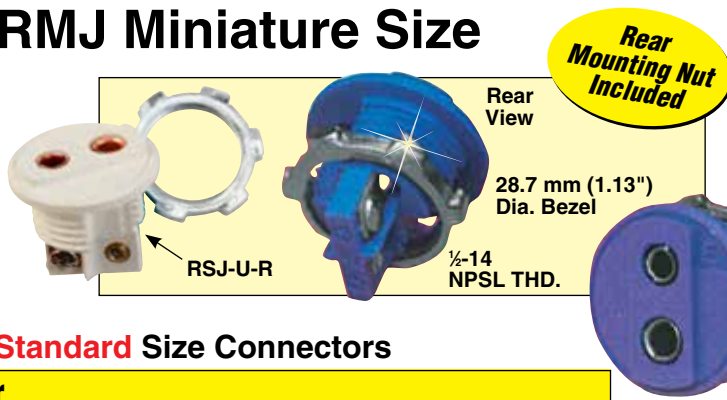

Accepts **Standard** Size Connectors

To Order		
Alloy Code	Color	Model No. Round Face
K	Yellow	RSJ-K-R
T	Blue	RSJ-T-R
J	Black	RSJ-J-R
E	Purple	RSJ-E-R
R/S	Green	RSJ-R/S-R
U	White	RSJ-U-R
N	Orange	RSJ-N-R

Ordering Example: RSJ-J-R, round face, round hole panel jack for use with Type J standard connector.
 * Also available in male configurations

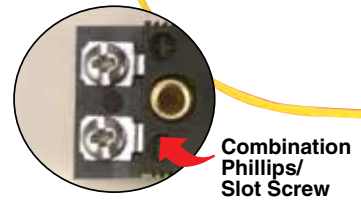

- ✓ Standard Accepts All Industry Standard Size Connectors
- ✓ Miniature Accepts All Industry Miniature Size Connectors
- ✓ Mounts in Round or "D" Punch Holes
- ✓ Polarity Keyed
- ✓ Color-Coded
- ✓ No Filing Required
- ✓ Glass-Filled Nylon Rated From -29 to 180°C (-20 to 356°F)

Note: Minor discoloration of connector may occur between 150°C (302°F) and 180°C (356°F). Electrical properties are not affected.



Easy Installation


No special tooling is required for installation. Just drill or punch a round hole in your panel and tighten the supplied nut. Ideal for single-circuit applications where the connector must blend with existing instrumentation. Thermocouple circuits can be added to existing panels with only minimal interruption of operations. Thermocouple grade alloys used to form the contacts preserve the accuracy of the circuit even in changing ambient temperatures.

We make running changes when technical advances allow. Check at time of ordering for additional features.

Accepts **Miniature** Size Connectors

To Order		
Alloy Code	Color	Model No. Round Face
K	Yellow	RMJ-K-R
T	Blue	RMJ-T-R
J	Black	RMJ-J-R
E	Purple	RMJ-E-R
R/S	Green	RMJ-R/S-R
U	White	RMJ-U-R
N	Orange	RMJ-N-R
C	Red	RMJ-C-R

Ordering Example: RMJ-K-R, round hole panel jack for use with Type K miniature connector.

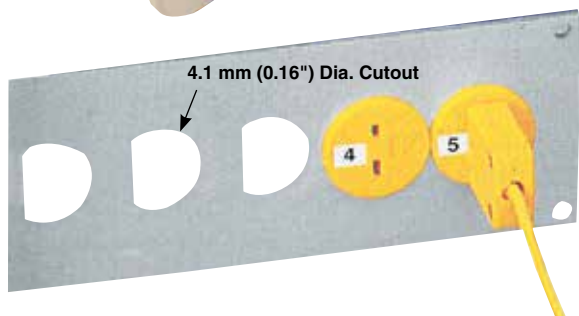

Extra miniature size mounting nuts, MH-RMJ-5 pkg of 5

