

# NEBO<sup>®</sup> BIG CRYKET™

The BIG CRYKET™ is a versatile 3-in-1 LED light, featuring a 300 lumen C-O-B work light, a bright 300 lumen spot light and an intense red light. Its unique swivel design allows the light's head to rotate into a forward-facing light, perfect for various working conditions. The magnetic base and steel clip provide convenient hands-free lighting.



### 3 LIGHT MODES

- Spot Light (300 lumens) - 5 hours / 140 meters
- C-O-B Work Light (300 lumens) - 3 hours / 20 meters
- Red (30 lumens) - 10 hours / 6 meters

### DESIGN

- Fully dimmable
- Power memory setting
- Direct-to-red feature
- Anodized aircraft-grade aluminum; water and impact-resistant
- 90° swivel head
- Dual-direction steel belt/pocket clip
- Powerful magnetic base
- Rubberized non-slip grip

### OPERATION

- Side-positioned, ON/OFF button

### BATTERIES

- Powered by 3 AA batteries (included)

### SPECS

- 0.5625 lbs.
- (H) 5.4375" x (W) 1.8125"

### PATENT PENDING



**Display Dimensions**  
(H) 14" x (W) 5.5" x (D) 7.75"

**Gift Box Dimensions**  
(H) 5.75" x (W) 3.1875" x (D) 2.625"

UPC CODE	ITEM	DESCRIPTION
645397932154	6666	BIG CRYKET

# NEBO<sup>®</sup> CRYKET™

The NEBO<sup>®</sup> CRYKET™ is a versatile 3-in-1 LED light, featuring a 240 lumen C-O-B work light, a bright 250 lumen spot light and an intense red or green light. Its unique swivel design allows the light's head to rotate into a forward-facing light, perfect for various working conditions. The magnetic base and steel clip provide convenient hands-free lighting.



### 3 LIGHT MODES

- Spot Light (250 lumens) - 3.5 hours / 113 meters
- C-O-B Work Light (240 lumens) - 2.75 hours / 21 meters
- Red (15 lumens) - 6.5 hours / 6 meters
- Green (30 lumens) - 3 hours / 8 meters [#6549 Camo]

### DESIGN

- Fully dimmable
- Anodized aircraft-grade aluminum; water and impact-resistant
- 90° swivel head
- Power memory setting
- Direct-to-red feature
- Steel belt/pocket clip
- Powerful magnetic base
- Rubberized non-slip grip

### OPERATION

- Top-positioned, ON/OFF button


### BATTERIES

- Powered by 4 AAA batteries (included)

### SPECS

- 0.3 lbs.
- (H) 4.825" x (W) 1.625"

### PATENT PENDING

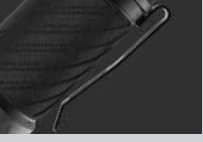

### AVAILABLE COLORS

- Smoke Gray
- Camo



**Display Dimensions**  
(H) 13" x (W) 5.5" x (D) 7.75"

**Gift Box Dimensions**  
(H) 4.825" x (W) 3" x (D) 2.325"

CALIFORNIA REQUIRED A WARNING  
Cancer and Reproductive Harm  
www.P65Warnings.ca.gov/product

UPC CODE	ITEM	DESCRIPTION
645397930914	6437	CRYKET™ with Display
645397931393	6549	CRYKET™ - Bulk Camo