


26 22 200 T




Snipe Nose Side Cutting Pliers with tether attachment point with tether attachment point

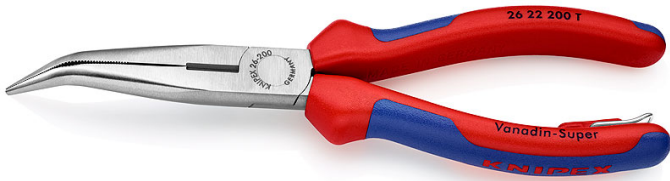

- Elastic tips: dimensionally stable even when twisted
- Distortion-tolerant, elastic precision tips
- Half-round, long, tapered jaws
- With cutting edges (hardness approx. 61 HRC) for soft, medium-hard and hard wire
- Vanadium electric steel, forged, multi stage oil-hardened
- Pliers with tether attachment point for mounting a fall protection



Article No.	26 22 200 T
EAN	4003773080008
Pliers	black atramentized
Head	polished
Handles	with multi-component grips, with integrated tether attachment point for a tool tether
Style	2
Insulation standard	IEC 60900 DIN EN 60900
Cutting capacities medium hard wire (diameter) Ø mm	3,2
Cutting capacities hard wire (diameter) Ø mm	2,2
L4 mm	23,0
T1 mm	9,5
W3 mm	18,0
W4 mm	3,0
T2 mm	2,5
L3 mm	73,0
Length mm	200
Net weight g	202

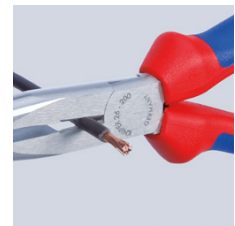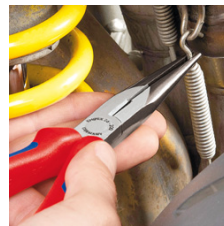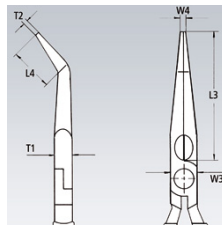

technical change and errors excepted