

70 05 180 T


Diagonal Cutter with tether attachment point



- The indispensable diagonal cutter for all-round use
- High-quality material and precise workmanship for long service life
- Precision cutting edges for soft and hard wire
- Clean cutting of thin copper wires, also at the cutting-edge tips
- Cutting edges additionally induction hardened, cutting edge hardness approx. 62 HRC
- Narrow head style for use in confined areas
- Vanadium electric steel, forged, multi stage oil-hardened
- Pliers with tether attachment point for mounting a fall protection



Article No.	70 05 180 T
EAN	4003773080039
Pliers	chrome plated
Head	
Handles	with multi-component grips, with integrated tether attachment point for a tool tether
Style	0
Cutting capacities medium hard wire (diameter) Ø mm	3,0
Cutting capacities hard wire (diameter) Ø mm	2,5
Cutting capacities soft wire (diameter) Ø mm	4,0
Length mm	180
Net weight g	258

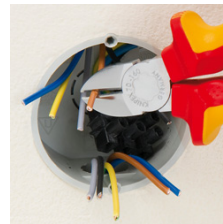

Slim head style and precise cut at blade tips: Advantageous when working in confined areas

technical change and errors excepted