

# 86 03 150




## Mini Pliers Wrench pliers and a wrench in a single tool



- Replaces the need for sets of metric and imperial spanners
- Smooth jaws for damage free installation of plated fittings - working directly on chrome!
- Adjustable tightening tool
- Also excellent for gripping, holding, pressing and bending workpieces
- Push the button for adjustment on the workpiece
- Zero backlash jaw pressure prevents damage to edges of sensitive components
- Parallel jaws give a more solid grip; its design allows flexible adjustment of all widths up to the specified maximum size
- Reliable catching of the hinge bolt: no unintentional shifting
- The ratchet type principle allows quick and easy tightening and release of all bolted connections
- Lever transmission greater than 10 : 1 for strong gripping power
- Chrome vanadium electric steel, forged, oil-hardened
- Ideal multi-purpose wrench in pocket size
- Indispensable companion in emergency tool kit


The smooth jaws grip all parallel surfaces in the capacity range with a high degree of pressure if necessary and open up almost unlimited application possibilities for the pliers wrench: e.g. for tightening locknuts, exerting pressure to activate the adhesive power of contact adhesives, edge breaking in tile work, snapping cable ties, utilisation as a small vice.

|                                 |                |
|---------------------------------|----------------|
| <b>Article No.</b>              | 86 03 150      |
| <b>EAN</b>                      | 4003773069676  |
| <b>Pliers</b>                   | chrome plated  |
| <b>Handles</b>                  | plastic coated |
| <b>B2 mm</b>                    | 7,0            |
| <b>B3 mm</b>                    | 10,5           |
| <b>B1 mm</b>                    | 4,7            |
| <b>Adjustment positions</b>     | 14             |
| <b>Capacities for nuts Inch</b> | 1              |
| <b>Capacities for nuts mm</b>   | 27             |
| <b>Length mm</b>                | 150            |
| <b>Net weight g</b>             | 175            |

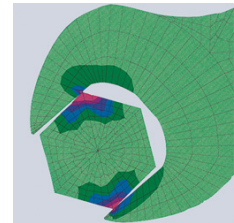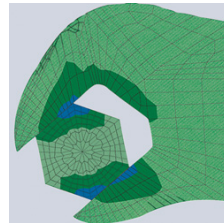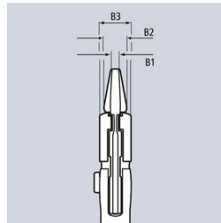

Pliers wrench: zero backlash contact pressure, no damage to edges

Conventional open end wrench: edge pressure causes surface damage

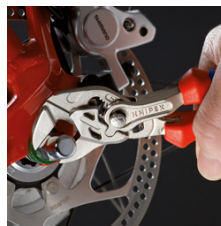

technical change and errors excepted



### Spare Parts

|                    |               |                                            |
|--------------------|---------------|--------------------------------------------|
| <b>Article No.</b> | <b>EAN</b>    |                                            |
| 86 09 150          | 4003773073123 | Range of spare parts adjustment for 86 150 |