

86 03 400




Pliers Wrench XL pliers and a wrench in a single tool



- The unique installation tool now also in 400 mm length
- For opening widths up to 85 mm / 3 3/8"
- Also excellent for gripping, holding, pressing and bending workpieces
- Optimised adjustment to the workpiece with hand-friendly position of grips
- Reliable catching of the hinge bolt: no unintentional shifting
- Lever transmission greater than 10 : 1 for strong gripping power
- Adjustable tightening tool
- Replaces diverse expensive, large open-end wrenches up to AF 85 mm or 3 3/8"
- Parallel jaws give a more solid grip; its design allows flexible adjustment of all widths up to the specified maximum size
- Smooth jaws, for damage free installation of quality union joints made from brass, red brass or stainless steel
- Zero backlash jaw pressure prevents damage to edges of sensitive components
- The ratchet type principle allows quick and easy tightening and release of all bolted connections
- Push the button for adjustment on the workpiece
- Chrome vanadium electric steel, forged, oil-hardened

Open-end wrenches with fixed opening widths are expensive, especially when used for large union joints. The KNIPEX Pliers Wrench XL , with their adjustable jaw opening up to AF 85 mm / 3 3/8", offer enormous savings potential here.

Article No.	86 03 400
EAN	4003773077312
Pliers	chrome plated
Handles	plastic coated
B2 mm	16
B3 mm	20
B1 mm	12,5
Adjustment positions	25
Capacities for nuts Inch	3 3/8
Capacities for nuts mm	85
Length mm	400
Net weight g	1460

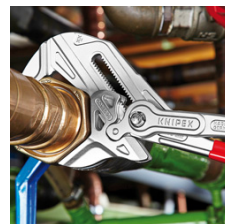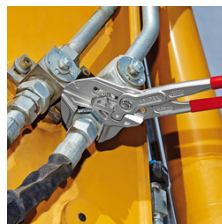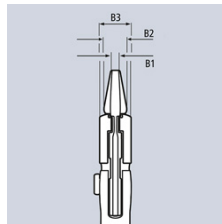

technical change and errors excepted

