

87 01 150

KNIPEX Cobra® Hightech Water Pump Pliers



- Push the button for adjustment on the workpiece
- Fine adjustment for optimum adaptation to different sizes of workpieces and a comfortable handle width
- Self-locking on pipes and nuts: no slipping on the workpiece and low handforce required
- Gripping surfaces with special hardened teeth, teeth hardness approx. 61 HRC: high wear resistance and stable gripping
- Box-joint design for high stability due to double guide
- Reliable catching of the hinge bolt: no unintentional shifting
- Guard prevents operators' fingers being pinched
- Chrome vanadium electric steel, forged, multi stage oil-hardened

KNIPEX Cobra® - the Hightech Water Pump Pliers. No more time-consuming presetting of the required opening size. Just position the upper jaw to the workpiece, push button and move close the lower jaw, ingeniously simple.


Article No.	87 01 150
EAN	4003773060116
Pliers	grey atramentized
Head	polished
Handles	with non-slip plastic coating
Adjustment positions	11
Capacity for pipes, inches (diameter) Ø Inch	1 1/4
Capacities for pipes (diameter) Ø mm	32
Capacities for nuts mm	30
Length mm	150
Net weight g	145




Fine adjustment by pushing a button: fast and comfortable.




Fast and firm adjustment directly on the workpiece

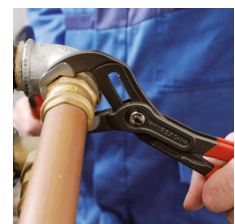

Teeth set against the direction of rotation have a self-locking effect and prevent slipping on the workpiece.

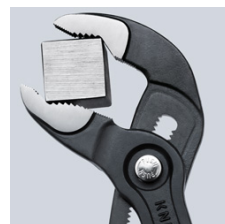

technical change and errors excepted

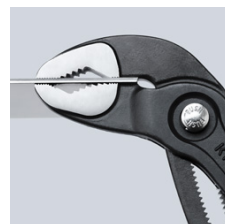



Spare Parts

Article No.	EAN	
87 09 150	4003773074168	Assortment of spare parts for adjustment for 87 150