

95 32 038

Cable Shears (ratchet action)

with telescopic handles



- Cable shears with adjustable telescopic handles allowing angular positioning
- For cable diameters up to 38 mm, handles can be positioned at an angle to set the optimum handle width, which makes the shear also suitable for work in confined areas
- Comfortable work thanks to ratchet action and low weight
- Heavy duty telescopic handles made of oval aluminium tubing; extendable up to 770 mm for maximum leverage on large cable diameters; retractable down to 570 mm for minimum space requirements during transport
- Replaceable cutting head
- Extensive cutting range up to max. Ø 38 mm or max. 280 mm² (e.g. 4 x 70 mm² NYY) in copper and aluminium cables
- Easier, neater cut due to optimised cutting-edge geometry
- Adjustable bolted joint
- Cutting head: special quality high-grade tool steel, oil-hardened
- Handles: high-strength oval aluminium tubing




Handles adjustable in length and angular position for easier work: set the handle length to the optimum lever for powerful cutting; put the handles at an angle for a comfortable gripping position


Article No.	95 32 038
EAN	4003773071556
Head	burnished
Handles	with multi-component grips
Cutting capacity copper cable, multiple-stranded (diameter) Ø mm	38
Cutting capacity copper cable, multiple-stranded mm²	280
MCM	550
Length mm	570
Net weight g	1980



Setting of a favourable handle width

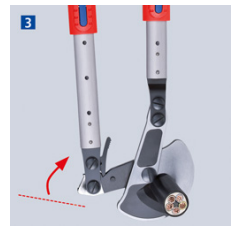

after the first partial cut, the handles open by ratchet action

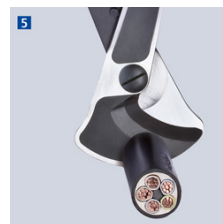

Repeat cutting and opening actions until the cable is cut through

technical change and errors excepted



Spare Parts

Article No.	EAN	
95 39 038	4003773073260	Spare cutter head for 95 32 038