


95 32 060

Cable Cutter (ratchet action)

with telescopic handles

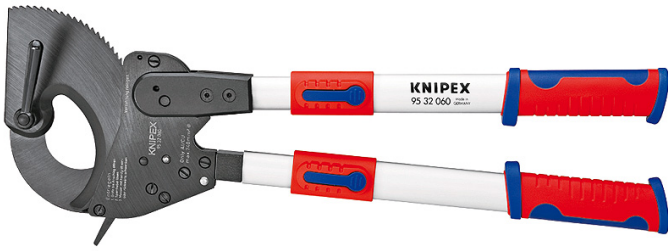

- For copper and aluminium single conductors as well as multiple stranded cables - also with hard rubber or plastic sheath
 - Not suitable for steel wire and wire ropes
 - Also suitable for cables with iron sheath reinforcement
 - Little hand force required for cutting due to optimum transmission ratio
 - High cutting capacity due to two-hand operation and ratchet action
 - The blade can be opened in any cutting position
 - Handle length with multiple position adjustment from 400 - 610 mm (short transport length, individual adaptation to working conditions)
 - Blade: special-quality high-grade tool steel, oil-hardened
 - Handles: high-strength oval aluminium tubing
- Tool length: 600 - 810 mm
• Weight only approx. 3820 g



Article No.	95 32 060
EAN	4003773071563
Head	burnished
Handles	with multi-component grips
Cutting capacity copper cable, multiple-stranded (diameter) Ø mm	60
Cutting capacity copper cable, multiple-stranded mm ²	740
MCM	1400
Length mm	630
Net weight g	3820



technical change and errors excepted



Spare Parts

Article No.	EAN	
95 39 720	4003773025290	Movable spare blade for 95 31 720 / 95 32 060 (ratchet action)