

ToughArmor

MB991IK-B

ICY DOCK®

www.icydock.com


2.5" SAS/ SATA Removable HDD Mobile Rack



SUPPORT
SATA 6Gbps



Anti-Vibration Design

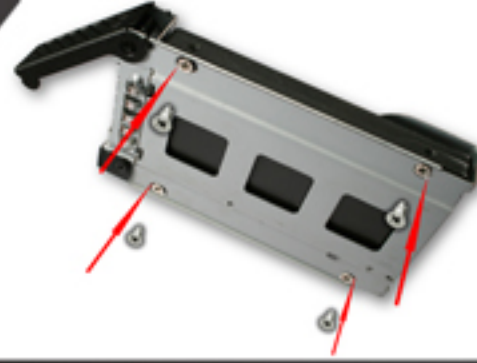

EZ-Slide Mini Tray System

3.5" Device Bay

Drive Tray Ejection Button

High Flow Air Vent

SATA / SAS Port

Security Key Lock

LED Indicator

● Green: Device Power
● Amber: Drive Activity

15 Pin SATA Power Port

SAS Port (Optional)



Drive Tray Compatible
To **MB994 Series**

MB991IK-B 2.5" SAS & SATA Mobile Rack Features

- **Heavy duty full metal construction** with suggested applications in Imaging, Medical, and Military systems, Media servers, and IPCs, approved & used by Tier 1 companies.
- **Fits 1 x 7mm to 15mm 2.5" SAS / SATA drives/ SSDs** in a 3.5" floppy drive bay.
- **Multi-Flow Technology** - provides excellent passive cooling.
- **Anti-Vibration Technology** - creates a safe environment for hard drives or SSDs.
- **Active Power Technology (APT)** - individual led only powers up if there is drive installed in the drive bay.
- **EMI Grounding** - protects hard drives from electrical damage.
- **Eagle-hook lock system & 2-segment safeguard key lock** keeps drives secure within the enclosure.
- **Anti-Dust Flap** prevents dust from entering when device not used.
- **Removable EZ Slide Mini Tray system** for easy maintenance.
- **Supports SAS 2.0 / SATA 6Gbps** and hot swap.
- **Single SATA 15 Pin** to power entire device.

Item Number:	MB991IK-B
Host Interface	2 x 7pin SATA (For SAS Dual Channel)
Drive Fit	Single 2.5" SAS or SATA I/ II/ III hard drive or SSD (7-15mm Height Drive)
Device Bay	3.5" floppy drive bay
Transfer Rate	Up to 6 Gb/sec per channel. (depending on HDD speed)
Power Input	Single 15pin SATA power port
Insert & Extract Connection Via	Direct SAS/ SATA hard drive connection
Structure	Full Metal
Drive Cooling	Metal heat dispersion
LED Indication	Device Power & Drive Activity
LED Display Color	Green : Device Power ; Amber : Drive Activity
Dimension (L x W x H)	5.32" x 4.00" x 1.01"
Weight	0.88 lbs