


**F1558**

Medium Rubber Foot

Material: Black Rubber

Part Number	Finish	Description	Diameter	Height
F1558	Black	Steel Washer	38.1mm / 1.5"	15.8mm / 5/8"
F1556	Black	Plastic version. No steel washer	38.1mm / 1.5"	15.8mm / 5/8"

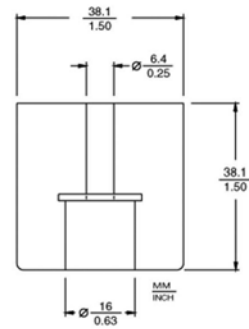


**9145**

Medium Rubber Foot with Steel Washer.

Material: Rubber

Part Number	Diameter	Height
9145	38.1mm / 1.5"	38.1mm / 1.5"

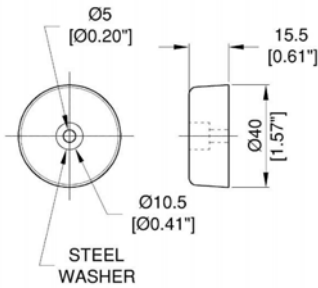


**F1686**

Large Rubber Foot with Steel Washer

Material: Black Rubber

Part Number	Diameter	Height
F1686	40mm / 1.57"	15.5mm / 5/8"
F1686/20	40mm / 1.57"	20mm / 13/16"
F1686/25	40mm / 1.57"	25mm / 1"

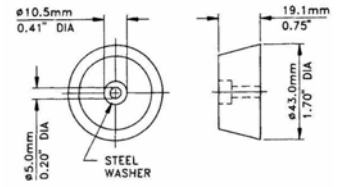


**F1615**

Large Rubber Foot with Steel Washer

Material: Black Rubber

Part Number	Diameter	Height
F1615	43mm / 1.69"	19.1mm / 3/4"

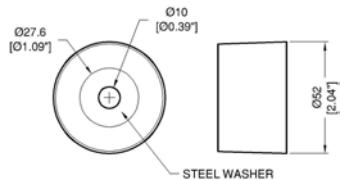


**9137**

Small Rubber Foot.  
Special Order outside USA & China

Material: Rubber

Part Number	Description	Diameter	Height
9137	Small Rubber Foot.	52mm / 2"	32mm / 1 1/4"

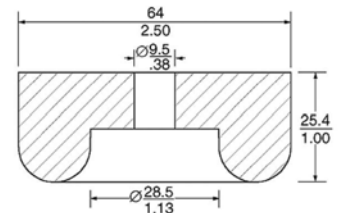

**9106**

Large Rubber Foot.  
Special Order outside USA & China

Material: Rubber

Part Number	Diameter	Height
9106	64mm / 2.5"	25.4mm / 1"