

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0391001803](#)
Status: **Active**
Overview: Eurostyle Two-Screw Barrier Strips
Description: 8.00mm Pitch Beau Eurostyle Two-Screw Terminal Strips, 3 Circuits

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

| | |
|----------------|--|
| Product Family | Terminal Blocks |
| Series | 39100 |
| Application | Wire-to-Wire |
| Component Type | One Piece |
| Overview | Eurostyle Two-Screw Barrier Strips |
| Product Name | Eurostyle Two Screw |
| Type | Barrier Strip |
| UPC | 78172545121 |

Physical

| | |
|-------------------------------|--------------------------------|
| Circuits (Loaded) | 3 |
| Circuits (maximum) | 3 |
| Color - Resin | White |
| Entry Angle | Horizontal |
| Lock to Mating Part | None |
| Material - Metal | Stainless Steel |
| Material - Resin | Nylon |
| Net Weight | 8.060/g |
| Number of Rows | 2 |
| Orientation | Vertical |
| PCB Retention | Yes |
| Panel Mount | Mounting Holes Between Circuit |
| Pitch - Mating Interface | 8.00mm |
| Pitch - Termination Interface | 8.00mm |
| Polarized to Mating Part | No |
| Stackable | No |
| Temperature Range - Operating | -40° to +105°C |
| Wire Size AWG | 12, 14, 16, 18, 20, 22 |

Electrical


| | |
|-------------------------------|-------|
| Current - Maximum per Contact | 20.0A |
| Voltage - Maximum | 600V |

Material Info

| | |
|--------------------|-----------------|
| Engineering Number | M800-01-03-5-M1 |
|--------------------|-----------------|

Reference - Drawing Numbers

| | |
|---------------|--------------|
| Sales Drawing | SD-39100-011 |
|---------------|--------------|

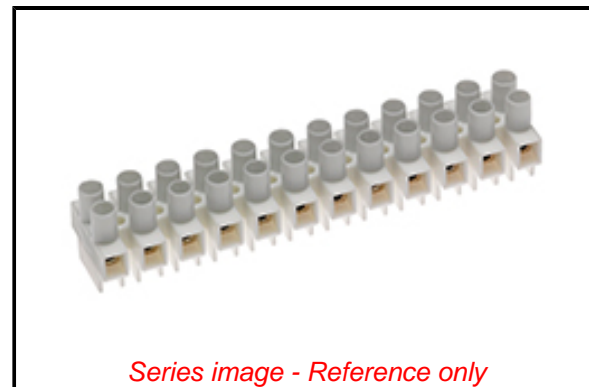

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - ED/61/2018 (27 June 2018)

Lead

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

| | |
|-----------------|------------------------|
| China ROHS | 50 Image |
| ELV | Not Relevant |
| Prop65 | Duty-To-Declare |
| PropRisk | Cancer |
| PropRisk | Developmental toxicity |
| PropRisk | Reproductive toxicity |
| PropSub | Lead and its compounds |
| RoHS Phthalates | Not Contained |

Search Parts in this Series

[39100](#) Series