


Part Number: [0002061132](#)
Status: Active
Overview: Standard .062" Pin and Socket Power Connectors
Description: 1.57mm Diameter, Standard .062" Pin and Socket Crimp Terminal, Series 1855, Female, with Tin (Sn) Plated Brass Contact, 24-30 AWG, Bag

Documents:

[図面 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[梱包仕様書 PK-1190-003 \(PDF\)](#)

一般用途	Power
Crimp Quality Equipment	有
概要	<u>Standard .062" Pin and Socket Power Connectors</u>
梱包違い製品	<u>02-06-1131 (Reel)</u>
製品名	Standard .062"
UPC	800753616042
機械的性能/材質	
ジェンダー	フィメール
材質 - 金属部	黄銅
材質 - 嵌合部メッキ	錫
材質 - ターミナルメッキ	錫
Net Weight	0.130/g
梱包形態	ポリ袋
嵌合部メッキ厚	0.508μm
ターミナルメッキ厚	0.508μm
実装スタイル	圧着またはコンプレッション
被覆外径	1.02-2.29mm
電線サイズ (AWG)	24, 26, 28, 30
Wire Size mm ²	N/A
参考情報	
Engineering Number	1855-(P901)L
図面・仕様書情報	
梱包仕様書	PK-1190-003
製品図面	SD-1855-*

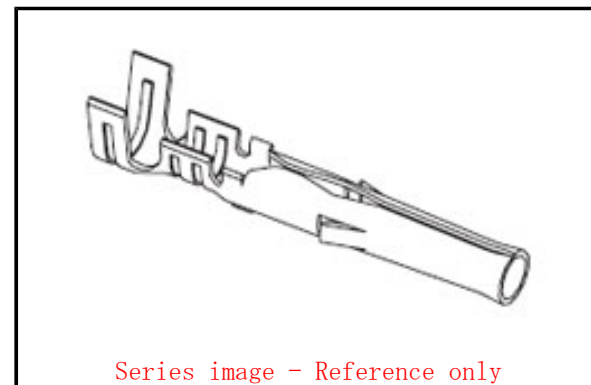

EU ELV
Not Relevant

EU RoHS China RoHS
Compliant

REACH SVHC
Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free
Status

Low-Halogen

For more information, please visit
[Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[1855 Series](#)