


Part Number: [0039000038](#)
 Status: Active
 Overview: [Mini-Fit Jr. Power Connectors](#)
 Description: Mini-Fit Female Crimp Terminal, Tin (Sn) over Copper (Cu) Plated Brass, 18-24 AWG, Reel

Documents:

図面 (PDF)	梱包仕様書 PK-5556-001-001 (PDF)
製品仕様書 PS-5556-001-001 (PDF)	Test Summary 55560000-TS-000 (PDF)
製品仕様書 PS-5556-002-001 (PDF)	RoHS Certificate of Compliance (PDF)
製品仕様書 TS-5556-002-001 (PDF)	

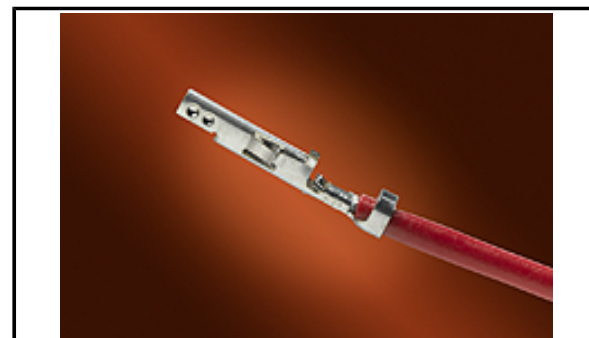

Series image - Reference only

一般用途	Power, 電線対基板, 電線対電線
Crimp Quality Equipment	有
概要	Mini-Fit Jr. Power Connectors
梱包違い製品	39-00-0039 (Loose)
製品名	Mini-Fit
UPC	800753585010
機械的性能/材質	
耐久挿抜回数	30
ジェンダー	フィメール
材質 - 金属部	黄銅
材質 - 嵌合部メッキ	錫
材質 - ターミナルメッキ	錫
Net Weight	0.453/g
梱包形態	リール
嵌合部メッキ厚	0.889µm
ターミナルメッキ厚	0.889µm
実装スタイル	圧着またはコンプレッション
被覆外径	1.30-3.10mm
電線サイズ (AWG)	18, 20, 22, 24
Wire Size mm ²	N/A
電気的性能	
最大定格電流	9.0A
最大定格電圧	600V
Solder Process Data	
Lead-freeProcess Capability	N/A
参考情報	
Engineering Number	5556T
図面・仕様書情報	
梱包仕様書	PK-5556-001-001
製品仕様書	PS-5556-001-001, PS-5556-002-001, TS-5556-002-001
製品図面	55560000-SD-000
Test Summary	55560000-TS-000

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit
[Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series
[5556 Series](#)

Mates With
[5558 Mini-Fit Crimp Male Terminals](#),
[Mini-Fit Jr. Header, Dual Row, 5566](#),
[5569](#)

Use With
[5557 Mini-Fit Jr. Receptacle Housing](#),
[30067 Mini-Fit TPA](#), [42474 Mini-Fit BMI](#)
Panel Mount