


Part Number: [0039000429](#)  
 Status: Active  
 Overview: [Mini-Fit Jr. Power Connectors](#)  
 Description: Mini-Fit Female Crimp Terminal, Selective Gold (Au) and Selective Tin (Sn) over Nickel (Ni), 18-24 AWG, Bag

Documents:

<a href="#">図面 (PDF)</a>	<a href="#">製品仕様書 PS-5556-002-001 (PDF)</a>
<a href="#">製品仕様書 PS-51010-007-001 (PDF)</a>	<a href="#">製品仕様書 TS-5556-002-001 (PDF)</a>
<a href="#">製品仕様書 PS-52034-005-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">製品仕様書 PS-5556-001-001 (PDF)</a>	

一般用途	Power, 電線対基板, 電線対電線有
Crimp Quality Equipment	有
概要	<a href="#">Mini-Fit Jr. Power Connectors</a>
梱包違い製品	<a href="#">39-00-0428 (Reel)</a>
製品名	Mini-Fit
UPC	822348149407
機械的性能/材質	
耐久挿抜回数	30
ジェンダー	フィメール
材質 - 金属部	黄銅
材質 - 嵌合部メッキ	金
材質 - ターミナルメッキ	錫
Net Weight	0.130/g
梱包形態	ポリ袋
嵌合部メッキ厚	0.762µm
ターミナルメッキ厚	2.540µm
実装スタイル	圧着またはコンプレッション
被覆外径	1.30-3.10mm
電線サイズ (AWG)	18, 20, 22, 24
Wire Size mm <sup>2</sup>	N/A
電気的性能	
最大定格電流	9.0A
最大定格電圧	600V
Solder Process Data	
Lead-freeProcess Capability	N/A
参考情報	
Engineering Number	5556GSL7F
図面・仕様書情報	
製品仕様書	PS-51010-007-001, PS-52034-005-001, PS-5556-001-001, PS-5556-002-001, TS-5556-002-001
製品図面	SD-5556-006-001

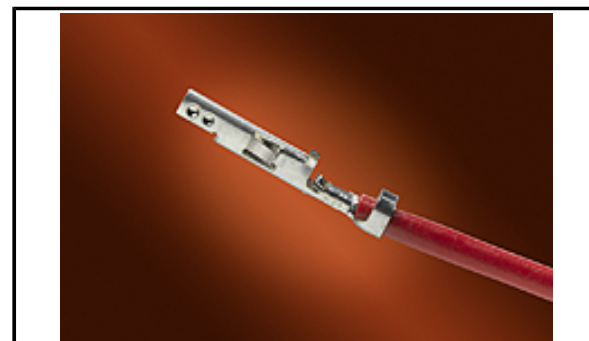

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -  
ED/61/2018 (27 June  
2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit  
[Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series  
[5556 Series](#)

Mates With

[5558 Mini-Fit Crimp Male Terminals](#),  
[Mini-Fit Jr. Header, Dual Row, 5566](#),  
[5569](#)

Use With

[5557 Mini-Fit Jr. Receptacle Housing](#)