


Part Number: [0391001810](#)
Status: Active
Overview: [Eurostyle Two-Screw Barrier Strips](#)
Description: 8.00mm Pitch Beau Eurostyle Two-Screw Terminal Strips, 10 Circuits

Documents:

[図面 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

一般用途	電線対電線
コンポーネント種別	One Piece
概要	Eurostyle Two-Screw Barrier Strips
製品名	Eurostyle Two Screw
タイプ	バリエーストリップ
UPC	78172545128
機械的性能/材質	
極数 (実装)	10
極数 (最大)	10
色 - 樹脂部	白色
挿入角度	水平
嵌合ロック	無
材質 - 金属部	ステンレス鋼
材質 - 樹脂部	ナイロン
Net Weight	26.880/g
列数	2
実装形態	ストレート
基板保持	有
パネルマウント	極間の実装孔
ピッチ - 嵌合部 (インチ)	8.00mm
ピッチ - 実装部	8.00mm
嵌合極性	無
縦列スタック (エンド・ツー・エンド)	無
使用温度範囲	-40° to +105° C
電線サイズ (AWG)	12, 14, 16, 18, 20, 22
電気的性能	
最大定格電流	20.0A
最大定格電圧	600V
参考情報	
Engineering Number	M800-01-10-5-M1
図面・仕様書情報	
製品図面	SD-39100-011

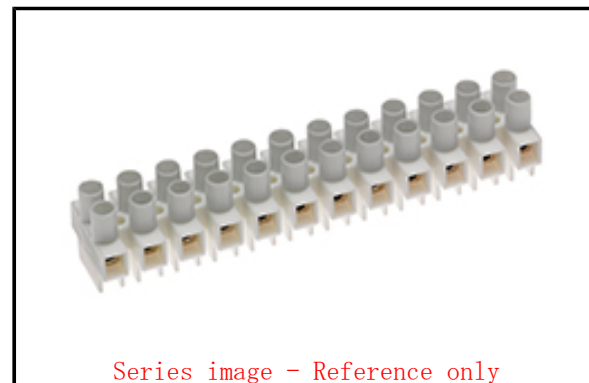

Series image - Reference only

EU ELV
Not Relevant

EU RoHS China RoHS

Compliant with
Exemption 6(c)
REACH SVHC
Contained Per -
ED/61/2018 (27 June
2018)

鉛
Halogen-Free
Status
Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for
any non-product compliance questions.

China ROHS	50 Image
ELV	Not Relevant
Prop65	Duty-To-Declare
PropRisk	Cancer
PropRisk	Developmental toxicity
PropRisk	Reproductive toxicity
PropSub	Lead and its compounds
RoHS Phthalates	Not Contained

Search Parts in this Series
[39100 Series](#)