


Part Number: [0430300007](#)  
 Status: Active  
 Overview: [Micro-Fit 3.0 Connector System Product Family](#)  
 Description: Micro-Fit 3.0 Crimp Terminal, Female, with Tin (Sn) Plated Phosphor Bronze Contact, 20-24 AWG, Bag

Documents:

<a href="#">図面 (PDF)</a>	<a href="#">梱包仕様書 PK-43030-003 (PDF)</a>
<a href="#">3Dモデル</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">製品仕様書 PS-43045 (PDF)</a>	<a href="#">Product Literature (PDF)</a>
<a href="#">製品仕様書 PS-43045-001 (PDF)</a>	

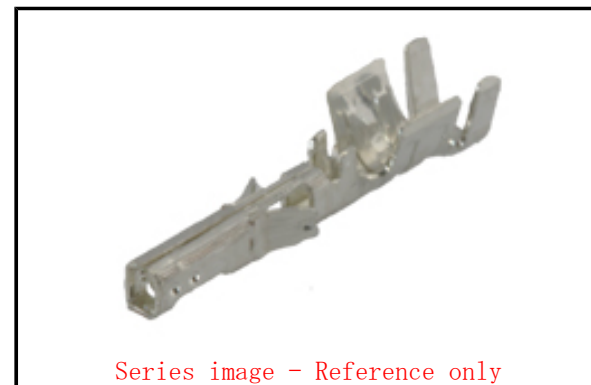

一般用途	Power, 電線対基板, 電線対電線
Crimp Quality Equipment	有
概要	<a href="#">Micro-Fit 3.0 Connector System Product Family</a>
梱包違い製品	<a href="#">43030-0001 (Reel)</a>
Product Literature Order No	987650-5984
製品名	Micro-Fit 3.0
UPC	800753755772

機械的性能/材質	
ジェンダー	フィメール
材質 - 金属部	りん青銅
材質 - 嵌合部メッキ	錫
材質 - ターミナルメッキ	錫
Net Weight	0.061/g
梱包形態	ポリ袋
嵌合部メッキ厚	1.016µm
ターミナルメッキ厚	1.016µm
実装スタイル	圧着またはコンプレッション
被覆外径	1.85mm max.
電線サイズ (AWG)	20, 22, 24
Wire Size mm <sup>2</sup>	N/A

電気的性能	
最大定格電流	8.5A

Solder Process Data	
Lead-freeProcess Capability	N/A

参考情報

図面・仕様書情報	
梱包仕様書	PK-43030-003
製品仕様書	PS-43045, PS-43045-001
製品図面	SD-43030-****

EU ELV	Not Relevant
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/61/2018 (27 June 2018)	
Halogen-Free Status	
Low-Halogen	
For more information, please visit <a href="#">Contact US</a>	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series  
[43030](#) Series

Use With  
[43025](#) , [43645](#) Micro-Fit 3.0 Receptacle Housings, [44133](#) Micro-Fit BMI Panel Mount Receptacle Housings