


Part Number: [0462350001](#)
 Status: Active
 Overview: [Micro-Fit 3.0 Connector System Product Family](#)
 Description: Micro-Fit RMF Reduced Mating Force, Crimp Terminal, Female, with 0.38µm Selective Gold (Au) over Nickel (Ni), 20-24 AWG, without Lubricant

Documents:

図面 (PDF)	梱包仕様書 PK-46235-001 (PDF)
製品仕様書 PS-46235-001-001 (PDF)	RoHS Certificate of Compliance (PDF)
製品仕様書 TS-46235-001-001 (PDF)	Product Literature (PDF)

一般用途コメント	Power, 電線対基板, 電線対電線 Up to 50% reduction in mating force
Crimp Quality Equipment	有
概要	Micro-Fit 3.0 Connector System Product Family
Product Literature Order No	987650-5984
製品名	Micro-Fit RMF
UPC	800756683485
機械的性能/材質	
耐久挿抜回数	40
ジェンダー	フィメール
材質 - 金属部	銅-亜鉛-錫
材質 - 嵌合部メッキ	金
材質 - ターミナルメッキ	ニッケル
Net Weight	0.046/g
梱包形態	リール
嵌合部メッキ厚	0.381µm
ターミナルメッキ厚	1.270µm
実装スタイル	圧着またはコンプレッション
被覆外径	1.85mm max.
電線サイズ (AWG)	20, 22, 24
Wire Size mm ²	N/A
電気的性能	
最大定格電流	5.0A
Solder Process Data	
Lead-freeProcess Capability	N/A
参考情報	
図面・仕様書情報	
梱包仕様書	PK-46235-001
製品仕様書	PS-46235-001-001, TS-46235-001-001
製品図面	SD-46235-001

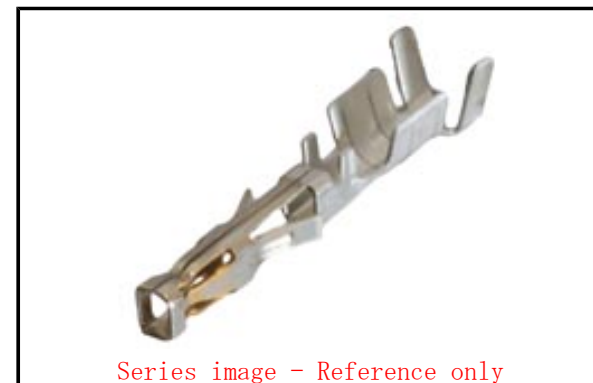

EU ELV
Compliant

EU RoHS
Compliant

REACH SVHC
Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free
Status

Low-Halogen

For more information, please visit
Contact US

China ROHS	Green Image
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
[46235](#) Series

Mates With
[43031](#) Micro-Fit 3.0 Male Crimp
Terminals

Use With
[43025](#) , [43645](#) Micro-Fit 3.0 Receptacle
Housings, [44133](#) Micro-Fit BMI Panel
Mount Receptacle Housings