


Part Number: [0676430910](#)  
 Status: Active  
 Overview: [USB Products and Solutions](#)  
 Description: Universal Serial Bus (USB) Shielded I/O Receptacle, Right-Angle, Type A, Black Polyester, Gold (Au) Flash, PCB Thickness 1.60mm, without Upper Flange, Lead-Free

Documents:

3Dモデル [製品仕様書 TS-67643-003-001 \(PDF\)](#)  
 図面 (PDF) [梱包仕様書 PK-67643-002 \(PDF\)](#)  
[製品仕様書 PS-67643-003-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

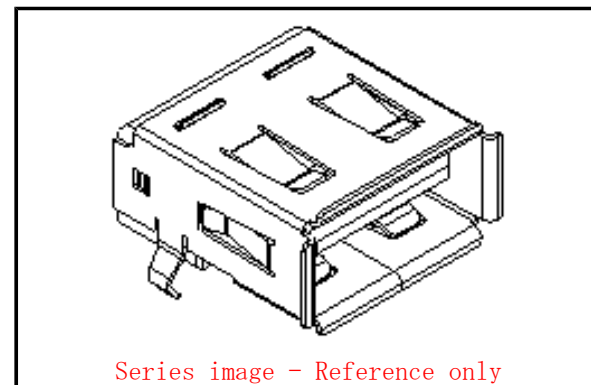

|                 |  |
|-----------------|--|
| 一般用途            | 電線対基板  |
| コメント            | Without Upper Flange Not for IR Reflow Process |
| コンポーネント種別       | リセプタクル   |
| 概要              | <a href="#">USB Products and Solutions</a>     |
| 製品名             | USB 2.0  |
| タイプ             | A  |
| UPC             | 822350071598                                   |
| 機械的性能/材質        |  |
| ブーツ色            | N/A  |
| 極数 (実装)         | 4  |
| 極数 (最大)         | 4  |
| ジェンダー           | リセプタクル   |
| 嵌合キー            | 有  |
| 嵌合ロック           | 有  |
| 材質 - 嵌合部メッキ     | 金  |
| 材質 - ターミナルメッキ   | 錫  |
| Net Weight      | 1.860/g  |
| 列数              | 1  |
| 実装形態            | ライトアングル  |
| 基板テール長          | 2.60mm   |
| 位置決め            | 有  |
| 基板保持            | 有  |
| 推奨基板厚           | 1.60mm   |
| 梱包形態            | トレイ  |
| パネルマウント         | 有  |
| ピッチ - 嵌合部 (インチ) | 2.00mm, 2.50mm                                 |
| ピッチ - 実装部       | 2.00mm, 2.50mm                                 |
| 嵌合極性            | 有  |
| 基板極性            | 有  |
| ポート             | 1  |
| 表面実装対応 (SMC)    | 無  |
| 使用温度範囲          | -40° to +85° C                                 |
| 実装スタイル          | スルーホール   |
| 防水 / 防塵         | 無  |
| 電气的性能           |  |
| 最大定格電流          | 1.5A   |
| シールド種別          | フルシールド   |
| シールド            | 有  |
| 最大定格電圧          | 30V DC   |

Solder Process Data

Duration at Max. Process Temperature (seconds) 003

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -  
ED/61/2018 (27 June  
2018)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit  
[Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series  
[67643 Series](#)

Mates With  
USB Type A Plug

Lead-freeProcess Capability  
Max. Cycles at Max. Process Temperature  
Process Temperature max. C

REFLOW  
001  
245

参考情報

図面・仕様書情報  
梱包仕様書  
製品仕様書  
製品図面

PK-67643-002  
PS-67643-003-001, TS-67643-003-001  
SD-67643-003

This document was generated on 09/27/2018  
PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION