

Part Number: [0530480410](#)
 Status: Active
 Overview: [PicoBlade Connector System](#)
 Description: 1.25mm Pitch PicoBlade Header, Right-Angle, 4 Circuits

Documents:

[3Dモデル](#) [梱包仕様書 SPK-53048-001-001 \(PDF\)](#)
[図面 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[製品仕様書 PS-51021-010-001 \(PDF\)](#)

Agency Certification

UL	E29179
一般用途	Signal, 電線対基板
Current Derating Order No	987651-3691
概要	PicoBlade Connector System
製品名	PicoBlade
UPC	800753565913

機械的性能/材質


分離型	無
極数 (実装)	4
極数 (最大)	4
色 - 樹脂部	自然色
活線挿抜対応	無
Glow-Wire Capable	無
嵌合ガイド	無
嵌合キー	無
嵌合ロック	有
嵌合高さ	3.50mm
材質 - 嵌合部メッキ	錫
材質 - 樹脂部	ナイロン
Net Weight	112.900/mg
列数	1
実装形態	ライトアングル
基板テール長	2.30mm
位置決め	無
基板保持	無
推奨基板厚	0.80mm
梱包形態	トレイ
ピッチ - 嵌合部 (インチ)	1.25mm
基板極性	無
シュラウド	フルシールド
縦列スタック (エンド・ツー・エンド)	無
使用温度範囲	-40° to +85° C
実装スタイル	スルーホール

電気的性能

最大定格電流	1.0A
最大定格電圧	125V

参考情報

図面・仕様書情報	
梱包仕様書	SPK-53048-001-001
製品仕様書	PS-51021-010-001
製品図面	SD-53048-**10, SD-53048-001

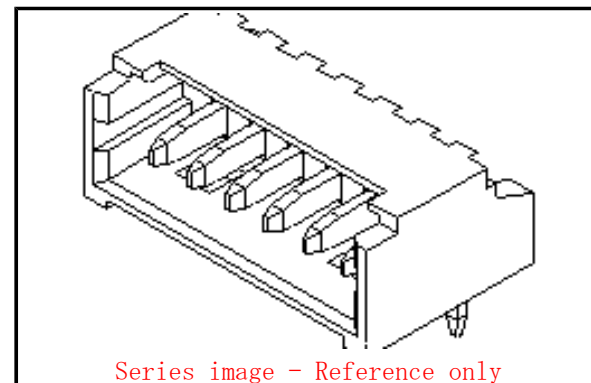

Series image - Reference only

EU ELV
Not Relevant

EU RoHS China RoHS

Compliant
 REACH SVHC
 Not Contained Per -
 ED/61/2018 (27 June
 2018)

Halogen-Free
 Status

Not Low-Halogen
 Need more information on product
 environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for
 any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
Prop65	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
[53048 Series](#)

Mates With
 PicoBlade Housing [51021](#)
PicoBlade
 Cable Assembly [15134](#)

This document was generated on 09/10/2018
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION