

Part Number:1053001200


Status:Active

Overview:Nano-Fit Power Connectors

Description:Nano-Fit Crimp Terminal, Female, 0.38μm Gold (Au) Plating, 24-26 AWG

Documents:	
図面 (PDF)	Test Summary 1053000000-TS-000 (PDF)
製品仕様書 PS-105300-100-001 (PDF)	RoHS Certificate of Compliance (PDF)
梱包仕様書 PK-105300-100-000 (PDF)	Product Literature (PDF)

一般	
用途	Power, 電線対基板
Crimp Quality Equipment	有
概要	Nano-Fit Power Connectors
Product Literature Order No	987651-1223
製品名	Nano-Fit
UPC	889056003254
機械的性能/材質	
耐久挿抜回数	50
ジェンダー	フィメール
材質 - 金属部	High Conductivity Copper
材質 - 嵌合部メッキ	Gold over Nickel
材質 - ターミナルメッキ	Tin over Nickel
Net Weight	0.100/g
梱包形態	リール
嵌合部メッキ厚	0.381μm
ターミナルメッキ厚	2.540μm
実装スタイル	圧着またはコンプレッション
被覆外径	1.30mm
電線サイズ (AWG)	24, 26
Wire Size mm ²	0.13-0.20
電気的性能	
最大定格電流	6.5A
最大定格電圧	250V AC (RMS)
参考情報	
図面・仕様書情報	
梱包仕様書	PK-105300-100-000
製品仕様書	PS-105300-100-001
製品図面	SD-105300-100-000
Test Summary	1053000000-TS-000

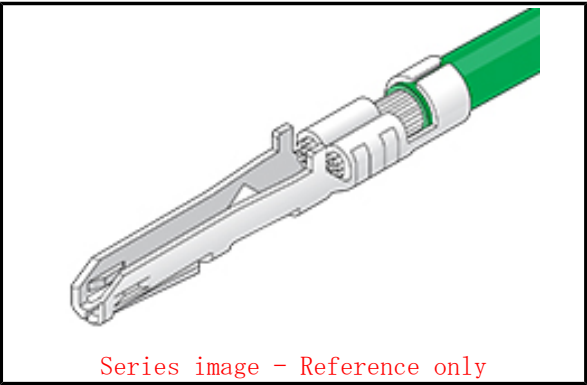

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per -	
ED/61/2018 (27 June	
2018)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit	
Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

105300 Series

Use With

Nano-Fit Receptacle Housing 105307 ,

105308