

Part Number: [0022057035](#)
 Status: Active
 Overview: [Mini-SPOX Wire-to-Board Connector System](#)
 Description: 2.50mm Pitch Mini-SPOX Wire-to-Board Header, Right-Angle, Shrouded, Friction Lock, 3 Circuits

Documents:

3Dモデル [梱包仕様書 SPK-5268-001-001 \(PDF\)](#)
 図面 (PDF) [RoHS Certificate of Compliance \(PDF\)](#)
 製品仕様書 PS-5264-001-001 (PDF)

Agency Certification


CSA LR19980
 UL E29179

一般用途概要製品名UPC
 用途 Signal, 電線対基板
 概要 [Mini-SPOX Wire-to-Board Connector System](#)
 製品名 Mini-SPOX
 UPC 800753592766

機械的性能/材質

分離型 無
 極数 (実装) 3
 極数 (最大) 3
 色 - 樹脂部 自然色
 耐久挿抜回数 30
 活線挿抜対応 無
 難燃性 94V-0
 Glow-Wire Capable 無
 嵌合ガイド 無
 嵌合キー 無
 嵌合ロック 有
 材質 - 嵌合部メッキ 錫
 材質 - ターミナルメッキ 錫
 材質 - 樹脂部 ナイロン
 Net Weight 344.400/mg
 列数 1
 実装形態 ライトアングル
 基板テール長 3.50mm
 位置決め 無
 基板保持 無
 推奨基板厚 1.60mm
 梱包形態 ポリ袋
 ピッチ - 嵌合部 (インチ) 2.50mm
 嵌合部メッキ厚 4.064µm
 ターミナルメッキ厚 4.064µm
 嵌合極性 有
 基板極性 無
 シュラウド フルシールド
 縦列スタック (エンド・ツー・エンド) 無
 表面実装対応 (SMC) 無
 使用温度範囲 -40° to +105° C
 実装スタイル スルーホール

電気的性能
 最大定格電流 3.0A

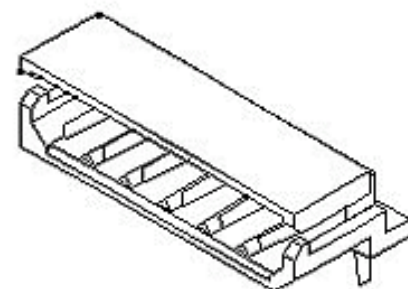

Series image - Reference only

EU ELV
 Not Relevant

EU RoHS China RoHS

Compliant
 REACH SVHC
 Not Contained Per -
 ED/61/2018 (27 June
 2018)

Halogen-Free
 Status

Not Low-Halogen
 Need more information on product
 environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for
 any non-product compliance questions.

China ROHS Green Image
 ELV Not Relevant
 Prop65 Compliant
 RoHS Phthalates Not Contained

Search Parts in this Series
[5268 Series](#)

Mates With
[5264 Mini-SPOX Wire-to-Board Crimp
 Housing](#)

最大定格電圧	250V
参考情報	
Engineering Number	5268-03A
図面・仕様書情報	
梱包仕様書	SPK-5268-001-001
製品仕様書	PS-5264-001-001
製品図面	SD-5268-NA

This document was generated on 09/10/2018
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION