

Part Number: [0470541000](#)
 Status: Active
 Overview: [KK® Interconnect System - Molex](#)
 Description: KK 254 Housing with Polarization Rib, 4 Pin

Documents:

[3Dモデル](#) [梱包仕様書 470541000-PK-000 \(PDF\)](#)
[図面 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[製品仕様書 PS-47053-001-001 \(PDF\)](#)

Agency Certification

UL	E29179
一般用途概要	Signal, 電線対基板
製品名	KK® Interconnect System - Molex
UPC	KK 254 822348237999

機械的性能/材質

極数 (最大)	4
色 - 樹脂部	アイボリー
難燃性	94V-0
ジェンダー	リセプタクル
Glow-Wire Capable	無
嵌合ロック	有
材質 - 樹脂部	ナイロン
Net Weight	0.522/g
列数	1
梱包形態	ポリ袋
パネルマウント	無
ピッチ - 嵌合部 (インチ)	2.54mm
ピッチ - 実装部	2.54mm
嵌合極性	有
縦列スタック (エンド・ツー・エンド)	無
使用温度範囲	See Product Specification

電気的性能

最大定格電流	4.0A
--------	------


Solder Process Data

Duration at Max. Process Temperature (seconds)	005
Lead-free Process Capability	N/A
Max. Cycles at Max. Process Temperature	001
Process Temperature max. C	230

参考情報

図面・仕様書情報

梱包仕様書	470541000-PK-000
製品仕様書	PS-47053-001-001
製品図面	SD-47054-001

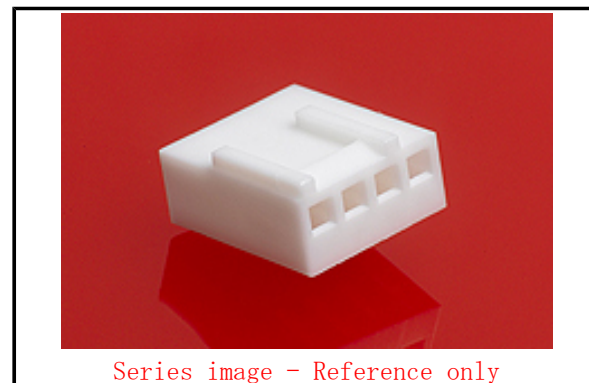

Series image - Reference only

EU ELV
Not Relevant

EU RoHS China RoHS
Compliant

REACH SVHC
Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free
Status

Low-Halogen

For more information, please visit
[Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[47054](#) Series

Mates With
[47053](#) 2.54mm Pitch KK Vertical Header,
with Friction Lock

Use With
[2759](#) KK Crimp Terminal, 22-30 AWG