

Part Number:5013310607

Status:Active

Overview:Pico-Clasp Wire-to-Board Connectors

Description:1.00mm Pitch Pico-Clasp Wire-to-Board Header, Surface Mount, Single Row, Vertical, Tin Plated, with Inner Positive Lock, with Pick-and-Place Tape, 6 Circuits

Documents:

3Dモデル

梱包仕様書 SPK-501331-001-001 (PDF)

図面 (PDF)

RoHS Certificate of Compliance (PDF)

製品仕様書 PS-501331-001-001 (PDF)

Agency Certification

UL

E29179

一般

用途Signal, 電線対基板

概要Pico-Clasp Wire-to-Board Connectors

製品名Pico-Clasp

UPC822348542871

機械的性能/材質

分離型無

極数 (実装)6

極数 (最大)6

色 - 樹脂部自然色

耐久挿抜回数30

Glow-Wire Capable無

嵌合ロック有

材質 - 金属部りん青銅

材質 - 嵌合部メッキ錫

材質 - ターミナルメッキ錫

材質 - 樹脂部ナイロン

Net Weight147.800/mg

列数1

実装形態ストレート

位置決め無

基板保持有

梱包形態エンボステーピング

ピッチ - 嵌合部 (インチ)1.00mm

嵌合極性有

基板極性無

自動実装対応吸着テープ

縦列スタック (エンド・ツー・エンド)無

使用温度範囲-40° to +105° C

実装スタイルSMT (表面実装)

電気的性能

最大定格電流1.0A

最大定格電圧50V AC (RMS)/DC


参考情報

図面・仕様書情報

梱包仕様書SPK-501331-001-001

製品仕様書PS-501331-001-001

製品図面5013310612-SD-000, SD-501331-002, SD-501331-004

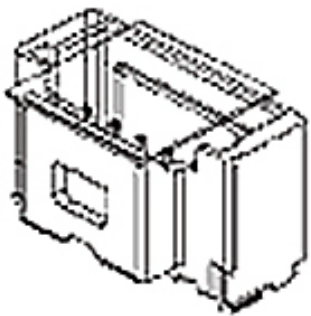

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per - ED/61/2018 (27 June 2018)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

501331 Series

Mates With

501330 Pico-Clasp Wire-to-Board Female Housing

This document was generated on 08/23/2018
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION