

Part Number: [5034801000](#)
 Status: Active
 Overview: [FFC-FPC \(SMT\)](#)
 Description: 0.50mm Pitch Easy-On Back Flip FPC Connector, 1.00mm Height, Right-Angle, Surface Mount, Dual Contact Style, 10 Circuits

Documents:

[3Dモデル](#) [梱包仕様書 SPK-503480-001 \(PDF\)](#)
[図面 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[製品仕様書 PS-503480-001 \(PDF\)](#)

Agency Certification

UL E29179

一般
 コメント Black Actuator
 概要 [FFC-FPC \(SMT\)](#)
 製品名 Easy-On
 UPC 884982040854

機械的性能/材質

Actuator Type Flip
 極数 (実装) 10
 色 - 樹脂部 Natural (White)
 コンタクト位置 両用
 耐久挿抜回数 10
 難燃性 94V-0
 嵌合高さ 1.00mm
 材質 - 金属部 りん青銅
 材質 - 嵌合部メッキ Gold over Nickel
 材質 - ターミナルメッキ Gold over Nickel
 材質 - 樹脂部 Liquid Crystal Polymer
 Net Weight 39.191/mg
 列数 1
 実装形態 ライトアングル
 位置決め 無
 PCB Mounting SMT (表面実装)
 基板保持 有
 梱包形態 エンボステーピング
 ピッチ - 嵌合部 (インチ) 0.50mm
 基板極性 有
 縦列スタック (エンド・ツー・エンド) 無
 使用温度範囲 -40° to +85° C
 ケーブル種別 FPCのみ

電気的性能


最大定格電流 0.5A
 最大定格電圧 50V AC (RMS)/DC

Solder Process Data

Duration at Max. Process Temperature (seconds) 003
 Lead-freeProcess Capability REFLOW
 Max. Cycles at Max. Process Temperature 002
 Process Temperature max. C 250

参考情報

[図面・仕様書情報](#)

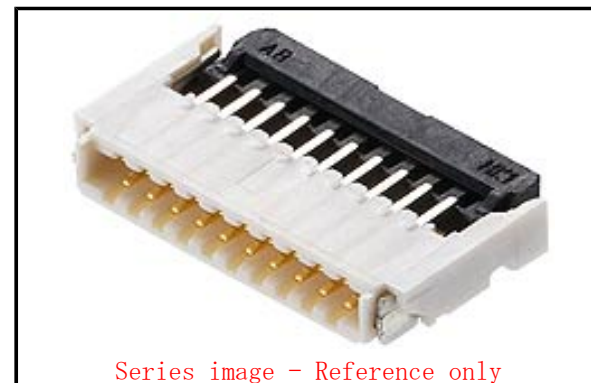

Series image - Reference only

EU ELV
 Not Relevant

EU RoHS [China RoHS](#)

Compliant
 REACH SVHC
 Not Contained Per -
 ED/61/2018 (27 June
 2018)

Halogen-Free
 Status

Low-Halogen

Need more information on product
 environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for
 any non-product compliance questions.

China ROHS [Green Image](#)
 ELV [Not Relevant](#)
 RoHS Phthalates [Not Contained](#)

Search Parts in this Series
[503480 Series](#)

梱包仕様書
製品仕様書
製品図面

SPK-503480-001
PS-503480-001
SD-503480-001, SD-503480-002

This document was generated on 09/03/2018
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION