


Part Number: [5051102491](#)
 Status: Active
 Overview: [FFC-FPC \(SMT\)](#)
 Description: 0.50mm Pitch Easy-On FFC/FPC Connector, 1.90mm Height, Double Bottom Contact Type (FD19 Series), Right-Angle, Surface Mount, ZIF, 24 Circuits

Documents:

[3Dモデル](#) [梱包仕様書 5051109200-200 \(PDF\)](#)
[図面 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[製品仕様書 PS-505110-001-001 \(PDF\)](#)

一般	
コメント	Black Actuator
概要	FFC-FPC (SMT)
製品名	Easy-On
UPC	887191626192
機械的性能/材質	
Actuator Type	Flip
極数 (実装)	24
極数 (最大)	24
色 - 樹脂部	ベージュ
コンタクト位置	下面
耐久挿抜回数	25
嵌合高さ	1.90mm
材質 - 金属部	りん青銅
材質 - 嵌合部メッキ	Gold over Nickel
材質 - ターミナルメッキ	Gold over Nickel
材質 - 樹脂部	Liquid Crystal Polymer
Net Weight	211.100/mg
列数	1
実装形態	ライトアングル
位置決め	無
PCB Mounting	SMT (表面実装)
基板保持	有
梱包形態	エンボステーピング
ピッチ - 嵌合部 (インチ)	0.50mm
ピッチ - 実装部	0.50mm
嵌合部メッキ厚	0.051µm
ターミナルメッキ厚	0.051µm
基板極性	有
縦列スタック (エンド・ツー・エンド)	無
使用温度範囲	-40° to +105° C
ケーブル種別	FFC/FPC
電気的性能	
最大定格電流	0.5A
最大定格電圧	50V AC (RMS)/DC
参考情報	
図面・仕様書情報	
梱包仕様書	5051109200-200
製品仕様書	PS-505110-001-001
製品図面	SD-505110-001, SD-505110-002

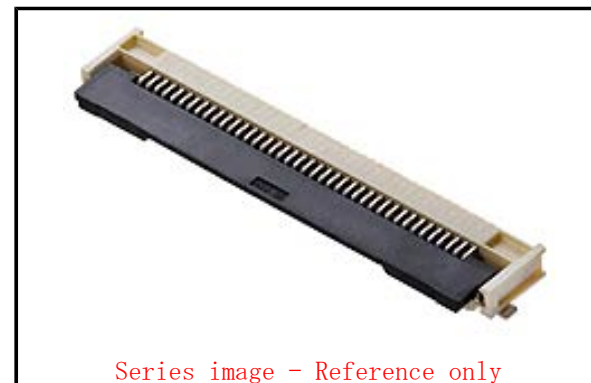

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit
[Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series
[505110 Series](#)

This document was generated on 09/28/2018
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION