

Part Number:0510650200

Status:Active


Description:2.00mm Pitch Micro-Latch Wire-to-Board Housing, Friction Lock, 2 Circuits, Natural

|                              |                                      |
|------------------------------|--------------------------------------|
| Documents:                   |                                      |
| 3Dモデル                        | 製品仕様書 PS-51065-017-001 (PDF)         |
| 図面 (PDF)                     | 製品仕様書 PS-51065-018-001 (PDF)         |
| 製品仕様書 510650000-000 (PDF)    | 梱包仕様書 SPK-51065-001-001 (PDF)        |
| 製品仕様書 PS-51065-005 (PDF)     | RoHS Certificate of Compliance (PDF) |
| 製品仕様書 PS-51065-016-001 (PDF) | Product Literature (PDF)             |

|                             |               |
|-----------------------------|---------------|
| Agency Certification        |               |
| CSA                         | LR19980       |
| UL                          | E29179        |
| 一般用途                        | Signal, 電線対基板 |
| Product Literature Order No | 987651-8983   |
| 製品名                         | Micro-Latch   |
| UPC                         | 800753630642  |

|                     |                 |
|---------------------|-----------------|
| 機械的性能/材質            |                 |
| 極数 (最大)             | 2               |
| 色 - 樹脂部             | 自然色             |
| 難燃性                 | 94V-0           |
| ジェンダー               | リセプタクル          |
| Glow-Wire Capable   | 無               |
| 材質 - 樹脂部            | Polyester       |
| Net Weight          | 68.000/mg       |
| 列数                  | 1               |
| 梱包形態                | ポリ袋             |
| パネルマウント             | 無               |
| ピッチ - 嵌合部 (インチ)     | 2.00mm          |
| 縦列スタック (エンド・ツー・エンド) | 無               |
| 使用温度範囲              | -40° to +105° C |

|          |                                                                                   |
|----------|-----------------------------------------------------------------------------------|
| 参考情報     |                                                                                   |
| 図面・仕様書情報 |                                                                                   |
| 梱包仕様書    | SPK-51065-001-001                                                                 |
| 製品仕様書    | 510650000-000, PS-51065-005, PS-51065-016-001, PS-51065-017-001, PS-51065-018-001 |
| 製品図面     | SD-51065-004, SD-51065-006                                                        |

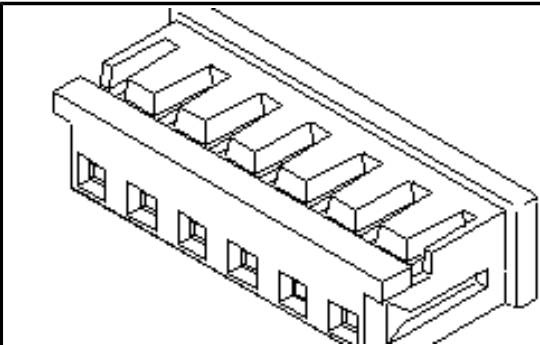

Series image - Reference only

EU ELV

Compliant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per -

ED/61/2018 (27 June

2018)

Halogen-Free

Status

Not Low-Halogen

Need more information on product

environmental compliance?

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)

Please visit the [Contact Us](#) section for

any non-product compliance questions.

|                 |               |
|-----------------|---------------|
| China ROHS      | Green Image   |
| ELV             | Compliant     |
| Prop65          | Compliant     |
| RoHS Phthalates | Not Contained |

Search Parts in this Series

51065 Series

Mates With

53253 PCB Header, 53254 PCB Header

Use With

50212 Crimp Terminal