

Part Number: [0511030400](#)
 Status: Active
 Description: 2.50mm Pitch Wire-to-Wire and Wire-to-Board Housing, Positive Lock, 4 Circuits, Natural

Documents:

3Dモデル	製品仕様書 PS-51103-025-001 (PDF)
図面 (PDF)	製品仕様書 PS-51103-026-001 (PDF)
製品仕様書 PS-51103-001 (PDF)	製品仕様書 PS-51103-027-001 (PDF)
製品仕様書 PS-51103-002 (PDF)	製品仕様書 PS-51103-028-001 (PDF)
製品仕様書 PS-51103-005-001 (PDF)	製品仕様書 PS-51198-003 (PDF)
製品仕様書 PS-51103-006 (PDF)	梱包仕様書 SPK-51103-001-001 (PDF)
製品仕様書 PS-51103-024-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E29179
一般用途	Signal, 電線対基板, 電線対電線
製品名	Mini-Lock
UPC	800753574090


機械的性能/材質

極数 (最大)	4
色 - 樹脂部	自然色
難燃性	94V-0
ジェンダー	リセプタクル
Glow-Wire Capable	無
嵌合キー	無
材質 - 樹脂部	Polyester
Net Weight	352.100/mg
列数	1
梱包形態	ポリ袋
パネルマウント	無
ピッチ - 嵌合部 (インチ)	2.50mm
縦列スタック (エンド・ツー・エンド)	無
使用温度範囲	-40° to +105° C

参考情報

図面・仕様書情報

梱包仕様書	SPK-51103-001-001
製品仕様書	PS-51103-001, PS-51103-002, PS-51103-005-001, PS-51103-006, PS-51103-024-001, PS-51103-025-001, PS-51103-026-001, PS-51103-027-001, PS-51103-028-001, PS-51198-003
製品図面	SD-51103-021, SD-51103-023

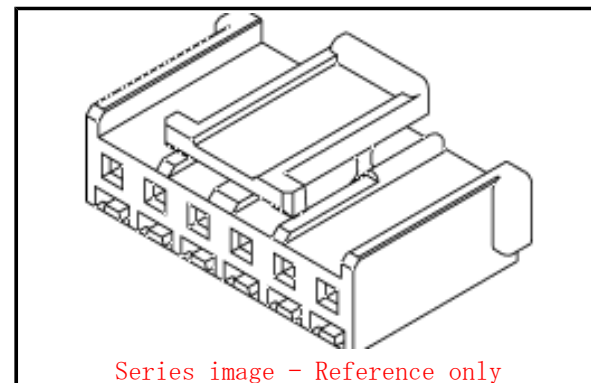

Series image - Reference only

EU ELV
Not Relevant

EU RoHS China RoHS

Compliant
REACH SVHC
Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free
Status

Not Low-Halogen
For more information, please visit
Contact US

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[51103 Series](#)

Mates With
[51198](#), [53375](#), [53426](#), [53517](#), [53608](#)

Use With
[50351](#), [50752](#)