

Part Number: [0522711279](#)
 Status: Active
 Overview: [FFC-FPC \(SMT\)](#)
 Description: 1.00mm Pitch Easy-On FFC/FPC Connector, Right-Angle, Surface Mount, ZIF, Bottom Contact Style, 12 Circuits, High Barrier Packaging

Documents:

[3Dモデル](#) [圧着仕様書 AS-52271-001-001 \(PDF\)](#)
[図面 \(PDF\)](#) [梱包仕様書 SPK-52271-002-001 \(PDF\)](#)
[製品仕様書 PS-52271-053-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

一般
 概要 [FFC-FPC \(SMT\)](#)
 製品名 Easy-On
 UPC 822348148714

機械的性能/材質


Actuator Type Slider
 極数 (実装) 12
 色 - 樹脂部 自然色
 コンタクト位置 下面
 耐久挿抜回数 30
 難燃性 94V-0
 嵌合高さ 3.00mm
 材質 - 金属部 りん青銅
 材質 - 嵌合部メッキ 錫-ビスマス
 材質 - ターミナルメッキ 錫-ビスマス
 材質 - 樹脂部 ナイロン
 Net Weight 164.000/mg
 列数 1
 実装形態 ライトアングル
 位置決め 無
 PCB Mounting SMT (表面実装)
 基板保持 有
 梱包形態 エンボステーピング
 ピッチ - 嵌合部 (インチ) 1.00mm
 ピッチ - 実装部 1.00mm
 基板極性 有
 縦列スタック (エンド・ツー・エンド) 無
 使用温度範囲 -40° to +85° C
 ケーブル種別 FFC/FPC

電気的性能

最大定格電流 0.5A
 最大定格電圧 50V AC (RMS)/DC

参考情報

図面・仕様書情報
 圧着仕様書 AS-52271-001-001
 梱包仕様書 SPK-52271-002-001
 製品仕様書 PS-52271-053-001
 製品図面 SD-52271-036-001, SD-52271-037

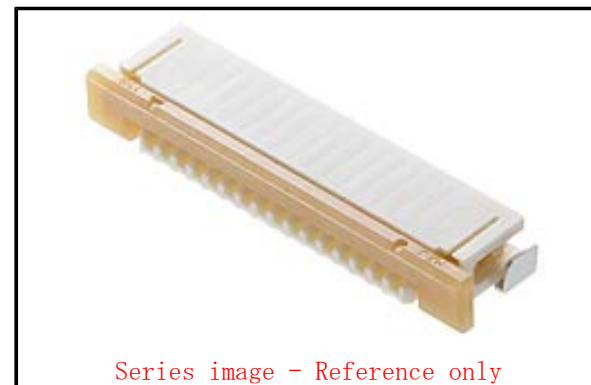

Series image - Reference only

EU ELV
 Not Relevant

EU RoHS [China RoHS](#)

Compliant
[REACH SVHC](#)
 Not Contained Per -
 ED/61/2018 (27 June
 2018)

[Halogen-Free](#)
[Status](#)

Not Low-Halogen

Need more information on product
 environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for
 any non-product compliance questions.

China ROHS [Green Image](#)
 ELV Not Relevant
 Prop65 Compliant
 RoHS Phthalates Not Contained

Search Parts in this Series
[52271 Series](#)

Mates With
http://www.molex.com/product/premoflex_ffc-fpc.html Molex Premo-Flex FFC. Be sure to match like plating

This document was generated on 09/11/2018
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION