


Part Number: [0524373071](#)
 Status: Active
 Overview: [FFC-FPC \(SMT\)](#)
 Description: 0.50mm Pitch Easy-On FFC/FPC Connector, Right-Angle, Surface Mount, ZIF, Bottom Contact Style, 30 Circuits, Gold (Au) Contact Plating

Documents:

[3Dモデル](#) [梱包仕様書 SPK-52437-001-001 \(PDF\)](#)
[図面 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[製品仕様書 PS-52437-027-001 \(PDF\)](#)

Agency Certification

UL	E29179
一般	
概要	FFC-FPC (SMT)
製品名	Easy-On
UPC	822348753413
機械的性能/材質	
Actuator Type	Slider
極数 (実装)	30
色 - 樹脂部	自然色
コンタクト位置	下面
耐久挿抜回数	20
難燃性	94V-0
材質 - 金属部	りん青銅
材質 - 嵌合部メッキ	金
材質 - ターミナルメッキ	金
材質 - 樹脂部	耐熱樹脂
Net Weight	377.100/mg
列数	1
実装形態	ライトアングル
位置決め	無
PCB Mounting	SMT (表面実装)
基板保持	無
梱包形態	エンボステーピング
ピッチ - 嵌合部 (インチ)	0.50mm
嵌合部メッキ厚	0.102µm
ターミナルメッキ厚	0.051µm
基板極性	有
縦列スタック (エンド・ツー・エンド)	無
表面実装対応 (SMC)	N/A
使用温度範囲	-40° to +85° C
ケーブル種別	FFC/FPC
電気的性能	
最大定格電流	0.5A
最大定格電圧	50V
参考情報	
図面・仕様書情報	
梱包仕様書	SPK-52437-001-001
製品仕様書	PS-52437-027-001
製品図面	SD-52437-019-001, SD-52437-020

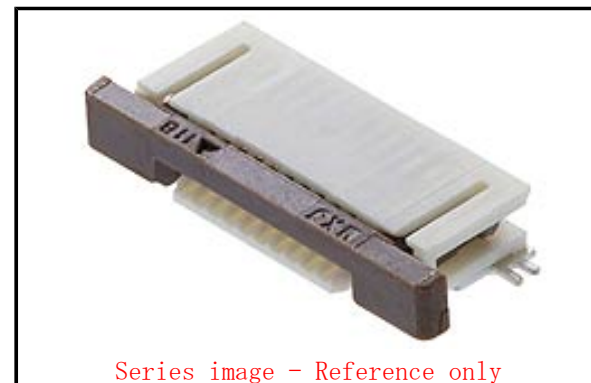

Series image - Reference only

EU ELV
Not Relevant

EU RoHS China RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free
Status

Not Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for
any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
Prop65	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
[52437 Series](#)

Mates With
Molex Premo-Flex FFC. Be sure to match like plating

This document was generated on 09/11/2018
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION