

Part Number: [0527462071](#)
 Status: Active
 Overview: [FFC-FPC \(SMT\)](#)
 Description: 0.50mm Pitch Easy-On FFC/FPC Connector, Right-Angle, Surface Mount, ZIF, Bottom Contact Style, 20 Circuits, Gold Contact Plating, High Barrier Packaging

Documents:

3Dモデル [梱包仕様書 SPK-52746-002-001 \(PDF\)](#)
 図面 (PDF) [RoHS Certificate of Compliance \(PDF\)](#)
 製品仕様書 PS-52746-015-001 (PDF)

Agency Certification

CSA LR19980
 UL E29179

一般概要
 製品名 [FFC-FPC \(SMT\)](#)
 UPC Easy-On
 822348157464

機械的性能/材質


Actuator Type Slider
 極数 (実装) 20
 コンタクト位置 下面
 耐久挿抜回数 20
 難燃性 94V-0
 嵌合高さ 2.00mm
 材質 - 金属部 りん青銅
 材質 - 嵌合部メッキ 金
 材質 - ターミナルメッキ 金
 Net Weight 228.960/mg
 列数 1
 実装形態 ライトアングル
 位置決め 無
 PCB Mounting SMT (表面実装)
 基板保持 有
 梱包形態 エンボステーピング
 ピッチ - 嵌合部 (インチ) 0.50mm
 基板極性 有
 縦列スタック (エンド・ツー・エンド) 無
 使用温度範囲 -40° to +85° C
 ケーブル種別 FFC/FPC

電気的性能

最大定格電流 0.5A
 最大定格電圧 50V

参考情報

図面・仕様書情報
 梱包仕様書 SPK-52746-002-001
 製品仕様書 PS-52746-015-001
 製品図面 SD-52746-024, SD-52746-025-001

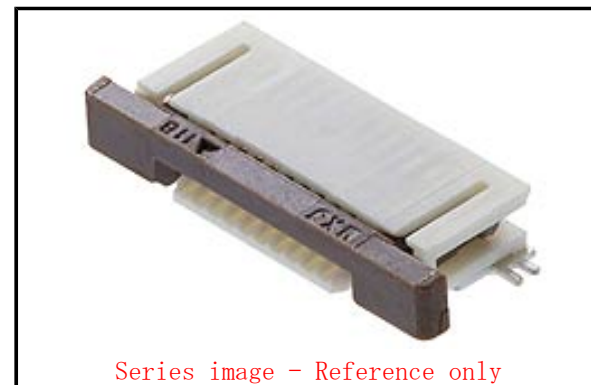

Series image - Reference only

EU ELV
 Not Relevant

EU RoHS [China RoHS](#)
 Compliant

REACH SVHC
 Not Contained Per -
 ED/61/2018 (27 June
 2018)

Halogen-Free
 Status

Not Low-Halogen

Need more information on product
 environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for
 any non-product compliance questions.

China ROHS [Green Image](#)
 ELV Not Relevant
 Prop65 Compliant
 RoHS Phthalates Not Contained

Search Parts in this Series
[52746 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION