

Part Number: [0533980671](#)
 Status: Active
 Overview: [PicoBlade Connector System](#)
 Description: 1.25mm Pitch PicoBlade Header, Surface Mount, Vertical, 6 Circuits

Documents:

[3Dモデル](#) [梱包仕様書 SPK-53398-002-001 \(PDF\)](#)
[図面 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[製品仕様書 PS-51021-024-001 \(PDF\)](#)

Agency Certification

UL E29179
 一般用途 Signal, 電線対基板
 Current Derating Order No 987651-3691
 概要 [PicoBlade Connector System](#)
 製品名 PicoBlade
 UPC 822348164332


機械的性能/材質

分離型 無
 極数 (実装) 6
 極数 (最大) 6
 色 - 樹脂部 自然色
 耐久挿抜回数 30
 活線挿抜対応 無
 難燃性 94V-0
 Glow-Wire Capable 無
 嵌合ガイド 無
 嵌合ロック 有
 嵌合高さ 5.70mm
 材質 - 金属部 りん青銅
 材質 - 嵌合部メッキ 錫
 材質 - ターミナルメッキ 錫
 材質 - 樹脂部 ナイロン
 Net Weight 214.700/mg
 列数 1
 実装形態 ストレート
 基板テール長 0.60mm
 位置決め 無
 基板保持 有
 梱包形態 エンボステーピング
 ピッチ - 嵌合部 (インチ) 1.25mm
 嵌合極性 有
 基板極性 有
 シュラウド 部分的
 縦列スタック (エンド・ツー・エンド) 無
 使用温度範囲 -40° to +85° C
 実装スタイル SMT (表面実装)

電気的性能
 最大定格電流 1.0A
 最大定格電圧 125V

参考情報

[図面・仕様書情報](#)

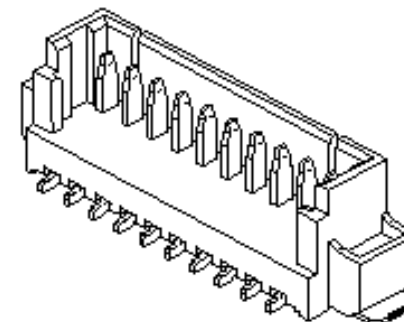

Series image - Reference only

EU ELV
 Not Relevant

EU RoHS [China RoHS](#)

Compliant
 REACH SVHC
 Not Contained Per -
 ED/61/2018 (27 June
 2018)

Halogen-Free
 Status

Not Low-Halogen
 Need more information on product
 environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for
 any non-product compliance questions.

China ROHS [Green Image](#)
 ELV [Not Relevant](#)
 Prop65 [Compliant](#)
 RoHS Phthalates [Not Contained](#)

Search Parts in this Series
[53398 Series](#)

Mates With
 PicoBlade Housing [51021](#)
PicoBlade
 Cable Assembly [15134](#)

梱包仕様書
製品仕様書
製品図面

SPK-53398-002-001
PS-51021-024-001
SD-53398-032, SD-53398-033-001

This document was generated on 09/10/2018
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION