

Part Number: [0533980871](#)
 Status: Active
 Overview: [PicoBlade Connector System](#)
 Description: 1.25mm Pitch PicoBlade Header, Surface Mount, Vertical, 8 Circuits

Documents:

[3Dモデル](#) [梱包仕様書 SPK-53398-002-001 \(PDF\)](#)
[図面 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[製品仕様書 PS-51021-024-001 \(PDF\)](#)

Agency Certification

UL	E29179
一般用途	Signal, 電線対基板
Current Derating Order No	987651-3691
概要	PicoBlade Connector System
製品名	PicoBlade
UPC	822348164356

機械的性能/材質


分離型	無
極数 (実装)	8
極数 (最大)	8
色 - 樹脂部	自然色
耐久挿抜回数	30
活線挿抜対応	無
難燃性	94V-0
Glow-Wire Capable	無
嵌合ガイド	無
嵌合ロック	有
嵌合高さ	5.70mm
材質 - 金属部	りん青銅
材質 - 嵌合部メッキ	錫
材質 - ターミナルメッキ	錫
材質 - 樹脂部	ナイロン
Net Weight	259.400/mg
列数	1
実装形態	ストレート
基板テール長	0.60mm
位置決め	無
基板保持	有
梱包形態	エンボステーピング
ピッチ - 嵌合部 (インチ)	1.25mm
嵌合極性	有
基板極性	有
シュラウド	部分的
縦列スタック (エンド・ツー・エンド)	無
使用温度範囲	-40° to +85° C
実装スタイル	SMT (表面実装)

電気的性能

最大定格電流	1.0A
最大定格電圧	125V

参考情報

[図面・仕様書情報](#)

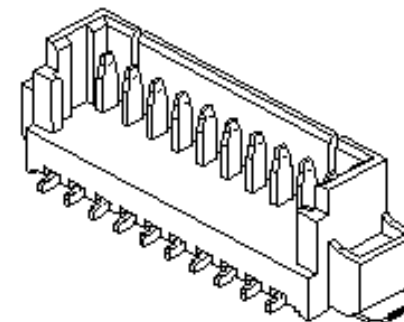

Series image - Reference only

EU ELV
Not Relevant

EU RoHS China RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free
Status

Not Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for
any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
Prop65	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
[53398 Series](#)

Mates With
PicoBlade Housing [51021](#)
PicoBlade
Cable Assembly [15134](#)

梱包仕様書
製品仕様書
製品図面

SPK-53398-002-001
PS-51021-024-001
SD-53398-032, SD-53398-033-001

This document was generated on 09/10/2018
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION