

Part Number: [0678038020](#)
 Status: Active
 Overview: [USB Products and Solutions](#)
 Description: USB On-The-Go (OTG) Mini-AB Receptacle, Right-Angle, Surface Mount, with Shell Tabs, Plastic Pegs and Cover Tape, Color Gray, Lead-Free

Documents:

3Dモデル [梱包仕様書 PK-67503-001 \(PDF\)](#)
 図面 (PDF) [RoHS Certificate of Compliance \(PDF\)](#)
 製品仕様書 PS-67803-001-001 (PDF)


一般用途	電線対基板
コンポーネント種別	リセプタクル
概要	USB Products and Solutions
製品名	USB 2.0, USB OTG (On-The-Go)
タイプ	Mini-AB (OTG)
UPC	822348781034

機械的性能/材質	
極数 (実装)	5
極数 (最大)	5
色 - 樹脂部	グレー
ジェンダー	リセプタクル
嵌合ロック	有
材質 - 金属部	銅合金
材質 - 嵌合部メッキ	金
材質 - ターミナルメッキ	錫
材質 - 樹脂部	ナイロン
Net Weight	0.685/g
列数	1
実装形態	ライトアングル
位置決め	有
基板保持	有
梱包形態	エンボステーピング
パネルマウント	無
ピッチ - 嵌合部 (インチ)	0.80mm
ピッチ - 実装部	0.80mm
嵌合部メッキ厚	0.762μm
ターミナルメッキ厚	3.810μm
嵌合極性	有
基板極性	有
ポート	1
使用温度範囲	0° to +50° C
実装スタイル	SMT (表面実装)

電気的性能	
最大定格電流	1.0A
シールド	有
最大定格電圧	30V

Solder Process Data	
Duration at Max. Process Temperature (seconds)	010
Lead-free Process Capability	REFLOW
Max. Cycles at Max. Process Temperature	001
Process Temperature max. C	260

参考情報

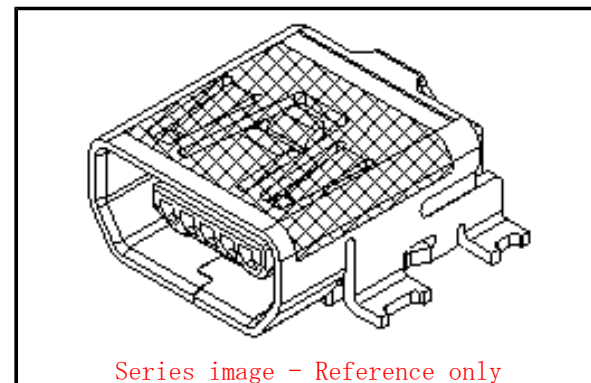

EU ELV
Not Relevant

EU RoHS [China RoHS](#)
Compliant

REACH SVHC
Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free
Status

Not Low-Halogen

For more information, please visit
[Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[67803 Series](#)

Mates With
USB OTG mini-A Plug, USB OTG mini-B
Plug, [88753 Cable Assembly](#)

図面・仕様書情報
梱包仕様書
製品仕様書
製品図面

PK-67503-001
PS-67803-001-001
SD-67803-002

This document was generated on 09/28/2018
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION