


Part Number: [0733910070](#)
 Status: Active
 Overview: [SMA RF Connectors](#)
 Description: 50 Ohms, SMA PCB Jack Receptacle, Vertical, with Standoffs, 80 Pieces Per Tray

Documents:

[3Dモデル](#) [RoHS Certificate of Compliance \(PDF\)](#)
[図面 \(PDF\)](#)

一般	
概要	SMA RF Connectors
製品名	SMA
スタイル	基板用ストレート
タイプ	Subminiature
UPC	800753926158
ケーブル種別	N/A
機械的性能/材質	
ジェンダー	ジャック
嵌合キー	無
Net Weight	1.474/g
実装形態	ストレート
PCB Mounting	スルーホール
推奨基板厚	3.00mm
梱包形態	トレイ
パネルマウント	無
パネルマウント方法	N/A
Reverse Polar	無
電气的性能	
Frequency	18 GHz
インピーダンス	50 Ω
Solder Process Data	
Duration at Max. Process Temperature (seconds)	010
Lead-freeProcess Capability	SMC&WAVE
Max. Cycles at Max. Process Temperature	002
Process Temperature max. C	260
参考情報	
図面・仕様書情報	
製品図面	SD-73391-007

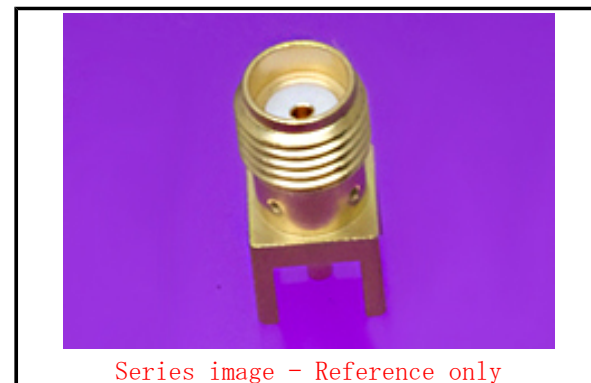

EU ELV
Not Relevant

EU RoHS China RoHS

Compliant with
Exemption 6(c)

REACH SVHC

Not Contained Per

-ED/01/2018 (15

January 2018)

Halogen-Free

Status

Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for
any non-product compliance questions.

China ROHS	50 Image
ELV	Not Relevant
Prop65	Duty-To-Declare
PropRisk	Cancer
PropRisk	Developmental toxicity
PropRisk	Reproductive toxicity
PropSub	Lead and its compounds
RoHS Phthalates	Not Contained

Search Parts in this Series
[73391 Series](#)