

Part Number: [0743204000](#)
Status: Active
Overview: [MicroCross DVI Connectors and Cable Assemblies](#)
Description: MicroCross DVI-D Digital Visual Interface, PCB Receptacle, Panel Mount, Polyester (PCT), Through Hole, 2.34mm PC Tail Length, Right-Angle, 0.76µm Gold (Au), Lead-Free, Screw Hole, 24 Circuits

Documents:

[3Dモデル](#) [梱包仕様書 PK-74320-010 \(PDF\)](#)
[図面 \(PDF\)](#) [Test Summary TS-74320-001 \(PDF\)](#)
[製品仕様書 PS-74320-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E29179


一般用途
コメント
コンポーネント種別
Electrical Model
概要
製品名
タイプ
UPC

電線対基板
DDWG (Digital Display Working Group) Standard
リセプタクル
有
[MicroCross DVI Connectors and Cable Assemblies](#)
MicroCross DVI
N/A
800754009980

機械的性能/材質

ブーツ色
極数 (実装)
極数 (最大)
色 - 樹脂部
耐久挿抜回数
難燃性
ジェンダー
嵌合キー
嵌合ロック
材質 - 金属部
材質 - 嵌合部メッキ
材質 - ターミナルメッキ
Net Weight
列数
実装形態
基板テール長
位置決め
基板保持
梱包形態
パネルマウント
ピッチ - 嵌合部 (インチ)
ピッチ - 実装部
嵌合部メッキ厚
ターミナルメッキ厚
嵌合極性
基板極性
ポート
表面実装対応 (SMC)
使用温度範囲
実装スタイル
防水 / 防塵

N/A
24
24
自然色
100
94V-0
リセプタクル
有
有
銅合金
金
錫
6.630/g
3
ライトアングル
2.34mm
有
有
トレー
有
1.90mm
1.90mm
0.762µm
2.540µm
有
有
1
無
-20° to +85° C
スルーホール
無

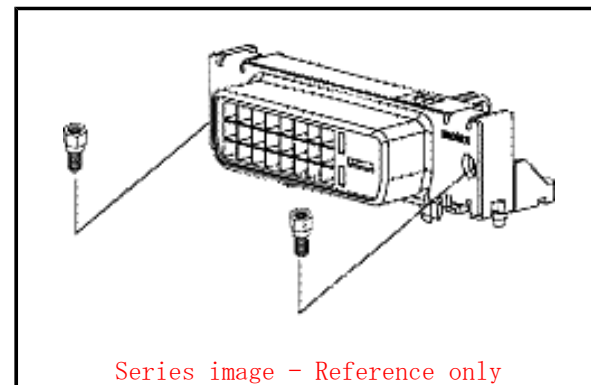

Series image - Reference only

EU ELV
Not Relevant

EU RoHS China RoHS

Compliant
REACH SVHC
Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free
Status

Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for
any non-product compliance questions.

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
[74320 Series](#)

Mates With
[88744](#) , [74323](#)

Use With
Hex Screw Kit [71781-1000](#) or [71781-2000](#)

電線サイズ (AWG)	N/A
電気的性能	
最大定格電流	3.0A
パネルグラウンド	有
シールド種別	フルシールド
シールド	有
最大定格電圧	40V AC (RMS)
Solder Process Data	
Duration at Max. Process Temperature (seconds)	010
Lead-free Process Capability	WAVE
Max. Cycles at Max. Process Temperature	001
Process Temperature max. C	260
参考情報	
図面・仕様書情報	
Electrical Model Document	EE-74320-001
梱包仕様書	PK-74320-010
製品仕様書	PS-74320-001
S-Parameter Model	SP-74320-001
製品図面	SD-74320-003-000
Test Summary	TS-74320-001

This document was generated on 08/16/2018
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION