

Part Number: [0874390600](#)  
 Status: Active  
 Overview: [Pico-SPOX Wire-to-Board Connector System](#)  
 Description: 1.50mm Pitch Pico-SPOX Wire-to-Board Housing, 6 Circuits, Off-White Housing

Documents:

<a href="#">3Dモデル</a>	<a href="#">製品仕様書 PS-87437-001-001 (PDF)</a>
<a href="#">図面 (PDF)</a>	<a href="#">梱包仕様書 SPK-87439-001-001 (PDF)</a>
<a href="#">製品仕様書 2027050000-000 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">製品仕様書 PS-78047-001-001 (PDF)</a>	<a href="#">Product Literature (PDF)</a>

Agency Certification

CSA	LR19980
UL	E29179

一般用途概要	Signal, 電線対基板
Product Literature Order No	<a href="#">Pico-SPOX Wire-to-Board Connector System</a>
製品名	USA-235
UPC	Pico-SPOX 800753537248

機械的性能/材質


極数 (最大)	6
色 - 樹脂部	自然色
難燃性	94V-0
ジェンダー	リセプタクル
Glow-Wire Capable	無
嵌合ロック	有
材質 - 樹脂部	ナイロン
Net Weight	80.000/mg
列数	1
梱包形態	ポリ袋
パネルマウント	無
ピッチ - 嵌合部 (インチ)	1.50mm
嵌合極性	有
縦列スタック (エンド・ツー・エンド)	無
使用温度範囲	-55° to +105° C

電気的性能

最大定格電流	2.5A
--------	------

参考情報

図面・仕様書情報	
梱包仕様書	SPK-87439-001-001
製品仕様書	2027050000-000, PS-78047-001-001, PS-87437-001-001
製品図面	SD-87439-***00

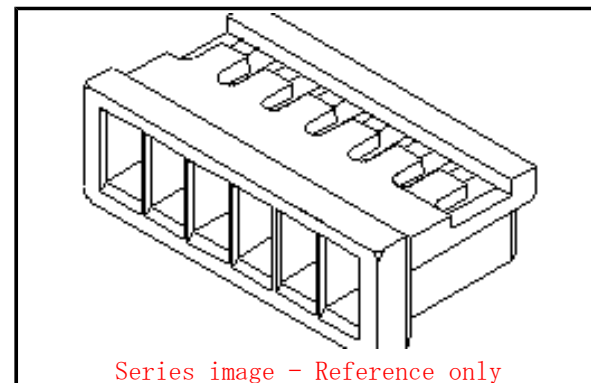

Series image - Reference only

EU ELV  
Compliant

EU RoHS China RoHS

Compliant

REACH SVHC

Not Contained Per -  
ED/61/2018 (27 June  
2018)

Halogen-Free  
Status

Low-Halogen

For more information, please visit  
Contact US

China ROHS	Green Image
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series  
[87439 Series](#)

Mates With  
Pico-SPOX Wire-to-Board Header [87437](#) ,  
[87438](#)

Use With  
[87421](#) Pico-SPOX Crimp Terminal