


Part Number: [1727040010](#)
Status: Active
Description: HPD Standard-Density D-Sub Receptacle Housing, Crimp, Panel Mount, 9 Circuits

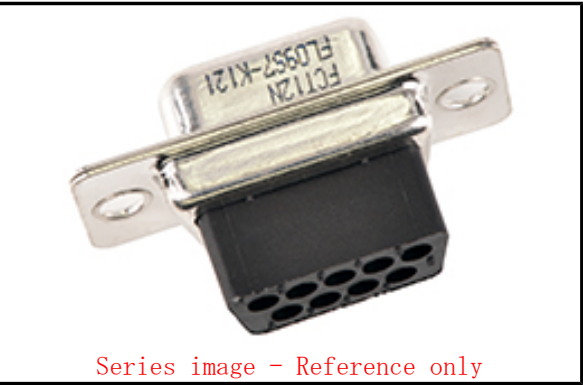

Series image - Reference only

Documents:	
RoHS Certificate of Compliance (PDF)	Product Literature (PDF)
一般	
Exclude SD Check	有
IP Rating	IP20
Product Category	リセプタクル
Product Literature Order No	987651-8284
製品名	HPD
タイプ	Standard Density
UPC	889056019118
機械的性能/材質	
極数 (実装)	0
極数 (最大)	9
色 - 樹脂部	黒色
耐久挿抜回数	500
ジェンダー	フィメール
嵌合ロック	無
Material - Frame	Tin-plated Steel
材質 - 樹脂部	Thermoplastic
Net Weight	0.005/g
列数	2
梱包形態	Carton
パネルマウント	有
パネルマウント方法	フランジ
嵌合極性	有
ポート	1
シールド	有
使用温度範囲	-55° to +130° C
防水 / 防塵	無
防水 / 防塵 種別	IP20
電気的性能	
最大定格電流	7.5A
参考情報	
Engineering Number	FL09S7-K121

EU ELV Compliant	
EU RoHS Compliant	China RoHS
REACH SVHC Not Contained Per - ED/61/2018 (27 June 2018) Halogen-Free Status Not Low-Halogen	
For more information, please visit Contact US	
China ROHS ELV RoHS Phthalates	Green Image Compliant Not Contained

Search Parts in this Series
[172704](#) Series

Mates With
D-sub, Size 1, 9 position, Plug

Use With
HPD Standard-Density Female Crimp
Contacts [173112-0214](#) , [173112-0215](#) ,
[173112-0216](#)